


E12565



Forbindelseskabel med AMP-kontakt

ADOGX060--A002E06

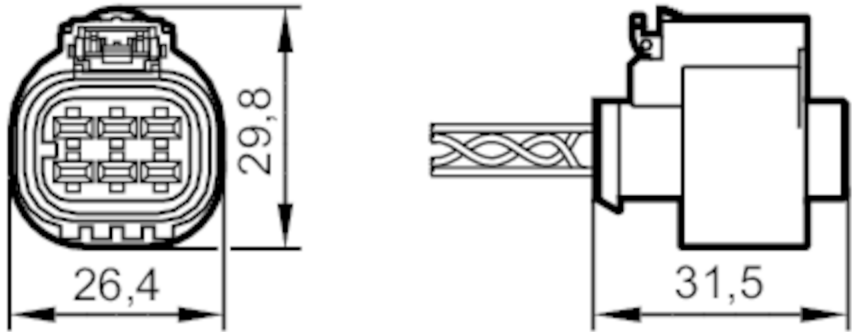

Elektriske data		
Driftsspenning	[V]	12,00...24,00 DC
Driftsforhold		
Omgivelsestemperatur	[°C]	-40,00...100,00
Omgivelsestemperatur (drivende)	[°C]	-40,00...100,00
Beskyttelse		IP 67; (paringskontakt plugget i)
Mekaniske data		
Vekt	[g]	246,40
Materialer		PBT
Merknader		
Antall i forpakning		1,00 stk.

E12565



Forbindelseskabel med AMP-kontakt


ADOGX060--A002E06

Elektrisk tilkobling

Kabel: 2 m, PVC; 4 x 2,5 mm² + 2 x 0,5 mm²

Elektrisk tilkobling - Stikkontakter

Tilkobling

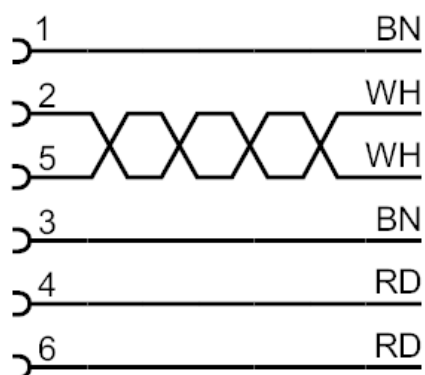

Lederfarger :
BN = brun
RD = rød
WH = hvit

Koblinger: 1 x AMP-kontakt, rett; kontakter: forniklet