


E12226



Ethernet-tilkoblingskabel

VSTAN040ZDS0002L04STGP040--S

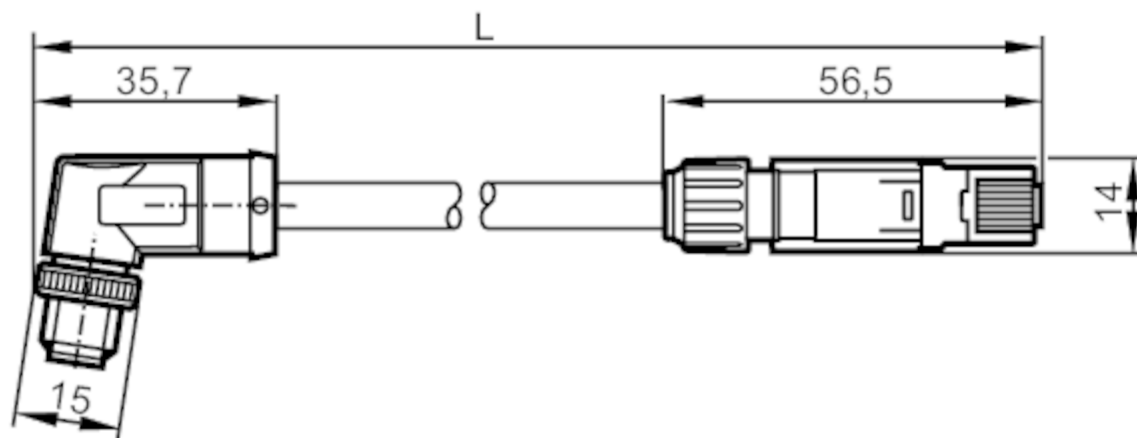

Applikasjon

Spesiell egenskap	gullbelagte kontakter; Skjermet kabel
Design	Ethernet-kabler, D-kodet
Applikasjon	cross-over patch-kabel; patchkabel

Driftsforhold

Omgivelsestemperatur	[°C]	-25,00...70,00
Beskyttelse		IP 67; IP 42; (M12/RJ45-plugg)

Mekaniske data

Vekt	[g]	167,20
Materialer		PUR/PC
Støpt kroppsmateriale		PUR / PC
Materiale mutter		diecast zinc, forniklet

Merknader

Antall i forpakning	1,00 stk.
---------------------	-----------

E12226



Ethernet-tilkoblingskabel

VSTAN040ZDS0002L04STGP040--S

Elektrisk tilkobling - koble M12


Koblinger: 1 x M12, vinklet; koding: D; Støpt kropp: PUR; låse: diecast zinc, forniklet; kontakter: gullbelagte; Tiltrekkingsmoment: 0,7...0,9 Nm



Elektrisk tilkobling

Kabel: 2 m, PVC, grønn, Ø 6,2 mm, beskyttet; 4 x 0,38 mm²

Tilkobling

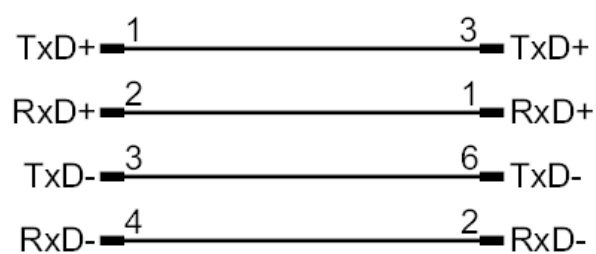

Elektrisk tilkobling - koble RJ45

Koblinger: 1 x RJ45, rett; Støpt kropp: PC

