




Reflektor for retrorefleksive lasersensorer

REFLECTOR LASER TS-10

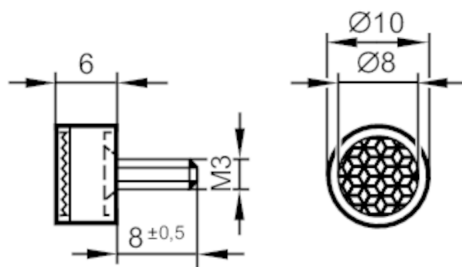

1 M3 8 mm dyp

Applikasjon

Design rund, for retrorefleksive lasersensorer, M3

Driftsforhold

Omgivelsestemperatur [°C] -10,00...60,00

Mekaniske data

Vekt [g] 2,30

Dimensjoner [mm] Ø 10,00 / L = 6,00

Reflektoroverflate [mm] Ø 8

Materialer skrue: rustfritt stål (1.4401 / 316); Fjærskive: rustfritt stål (1.4401 / 316); mutt: rustfritt stål (1.4401 / 316); frontpanel: PMMA; base: ABS

Merknader

Antall i forpakning 1,00 stk.