



Reflektor for retrorefleksive lasersensorer

REFLECTOR LASER TS-11X11

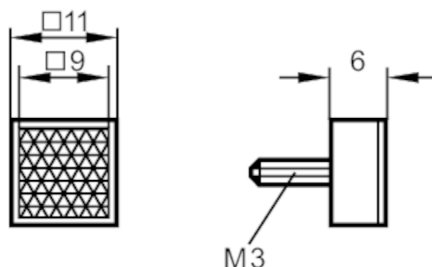

1 M3 8 mm dyp

Applikasjon

Design	rektangulær, for retrorefleksive lasersensorer, M3
--------	--

Driftsforhold

Omgivelsestemperatur	[°C]	-10,00...60,00
----------------------	------	----------------

Mekaniske data

Vekt	[g]	2,60
Dimensjoner	[mm]	11,00 x 11,00 x 6,00
Reflektorovertflate	[mm]	9 x 9
Materialer		skrue: rustfritt stål (1.4401 / 316); Fjærskive: rustfritt stål (1.4401 / 316); mutt: rustfritt stål (1.4401 / 316); frontpanel: PMMA; base: ABS

Merknader

Antall i forpakning	1,00 stk.
---------------------	-----------