


E21120

Vinkelbraketter

O4 STANDARD BRACKET

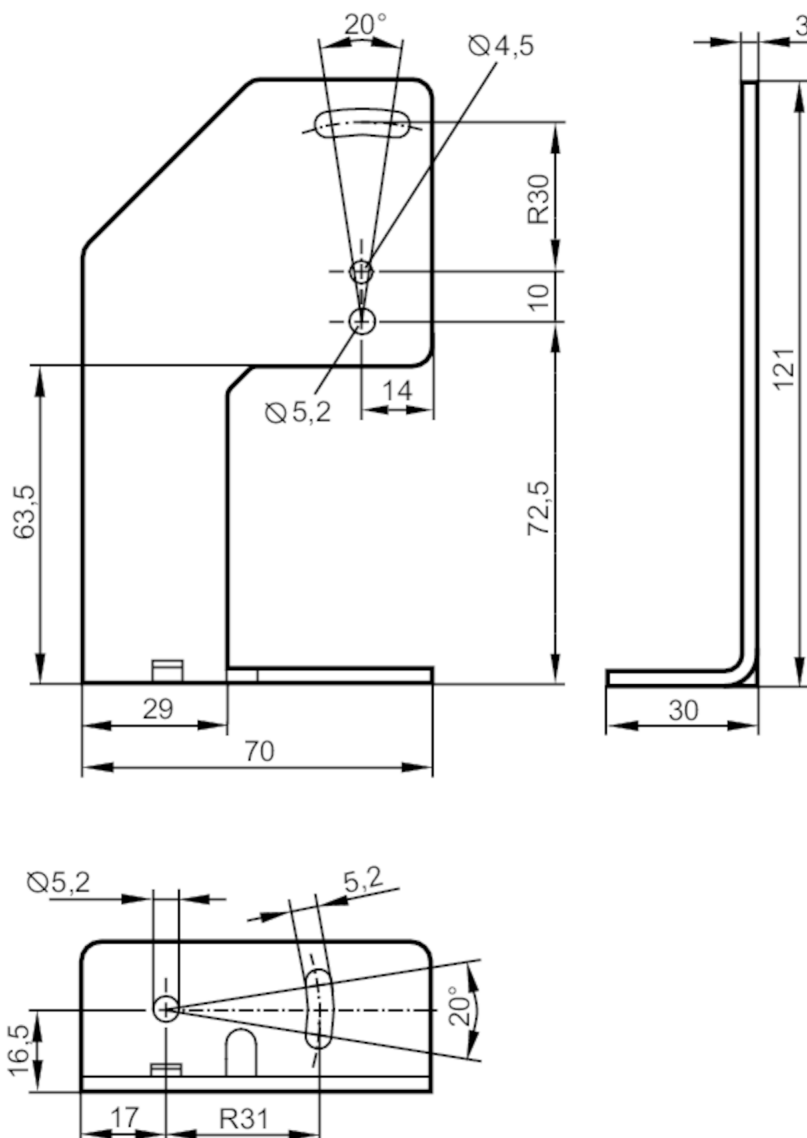

Applikasjon

Design

for type O4

Mekaniske data

Vekt

[g]

212,50

Dimensjoner

[mm]

121,00 x 30,00 x 70,00

Materialer

rustfritt stål (1.4404 / 316L)

Tilbehør

Varer som leveres

sylander skruer: 2 x M5 x 35

Mutter: 2

skiver: 2

sylander skruer: 2 x M4 x 45

Mutter: 2

skiver: 2

E21120



Vinkelbraketter

O4 STANDARD BRACKET

Merknader

Antall i forpakning	1,00 stk.
---------------------	-----------