


Kabelkompatibelt støpsel

SDOGK120MKRFKSG

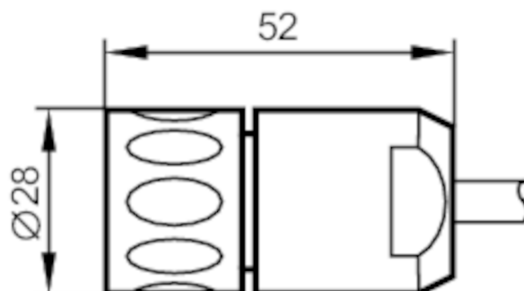

Elektriske data

Driftsspenning	[V]	4,50...30,00 DC
----------------	-----	-----------------

Driftsforhold

Omgivelsestemperatur	[°C]	-40,00...125,00
Beskyttelse		IP 67

Mekaniske data

Vekt	[g]	43,00
Dimensjoner	[mm]	28,00 x 28,00 x 52,00
Materialer		messing i plastkappe; PA 6,6 svart
Støpt kroppsmateriale		messing / PA 6.6, i plastkappe
Materiale mutter		messing, i plastkappe / PA 6,6, i plastkappe

Merknader

Antall i forpakning	1,00 stk.
---------------------	-----------


Elektrisk tilkobling

loddning: ...1 mm²

Elektrisk tilkobling - Stikkontakter

Koblinger: 1 x M23, rett; Støpt kropp: messing / PA 6.6, i plastkappe; låse: messing, i plastkappe

Koblinger: 1 x M23, rett; Støpt kropp: messing / PA 6.6, i plastkappe; låse: PA 6,6, i plastkappe

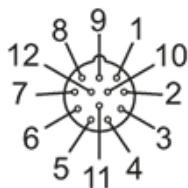

E60122



Kabelkompatibelt støpsel

SDOGK120MKRFKSG

Tilkobling

