


E70440



Doppelkaefigzugfederklemme

Double cage clamps / 6 pcs.

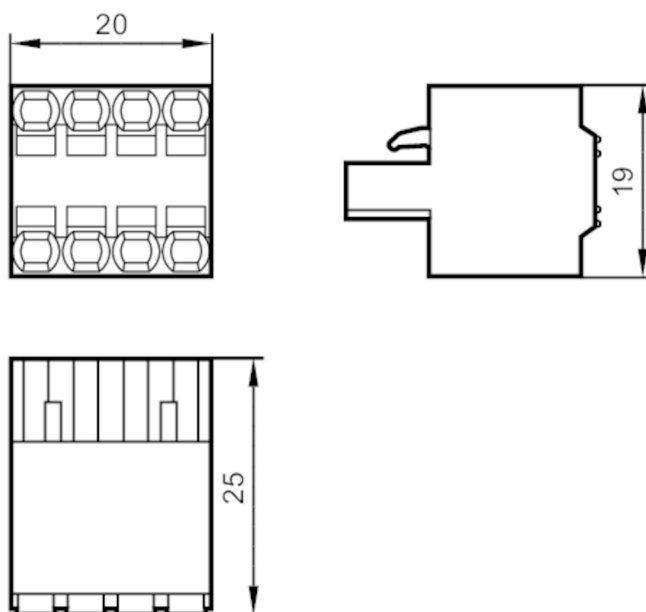

Elektriske data

Maks. lekkasjestrøm [A] 10,00; (2,5 mm²)

Driftsforhold

Omgivelsestemperatur [°C] -40,00...105,00

Mekaniske data

Vekt [g] 36,30

Materialer strømbelastningsdeler: kopplerlegering fortinnet; PA

Tiltrekkingsmoment [Nm] 0,50

Merknader

Antall i forpakning 6,00 stk.

Elektrisk tilkobling

0,2...2,5 mm²; Abisolierlänge: 10...12 mm