




AS-Interface strømfordeler

QUAD M12 AS-i/24V 4A

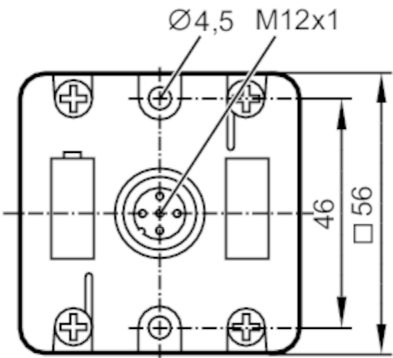

Applikasjon

Design	AS-i / 24 V
--------	-------------

Elektriske data

Driftsspenning	[V]	26,50...31,60 DC
Maks. nåværende belastning totalt	[A]	2,00
Ekstra spenningsforsyning	[V]	24,00 DC

Driftsforhold

Omgivelsestemperatur	[°C]	-25,00...75,00
Beskyttelse		IP 65

Mekaniske data


Vekt	[g]	95,50
Materialer		PA 6,6; Stikkontakter: rustfritt stål (1.4404 / 316L); skruer: rustfritt stål (1.4404 / 316L); mutt: rustfritt stål (1.4404 / 316L); O-ring: NBR; flatkabeltetning: NBR

Merknader

Antall i forpakning	1,00 stk.
---------------------	-----------

Elektrisk tilkobling

Koblinger: M12; koding: A

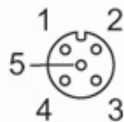

1	AS-i +
2	0V
3	AS-i -
4	+24V
5	funksjonell jord