


E70230



Skrueterminaler

Screw terminals / 6 pcs.

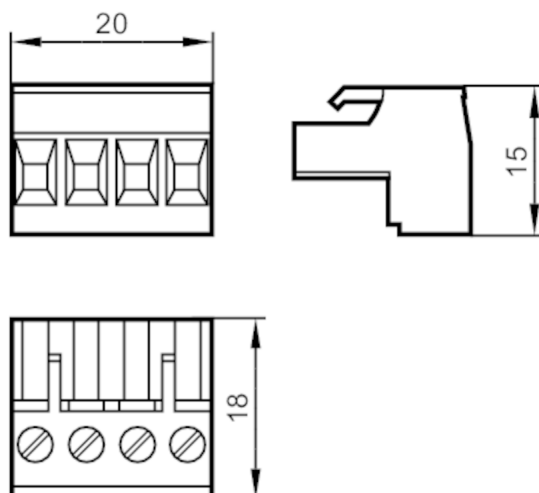

Elektriske data

Maks. lekkasjestrøm [A] 20,00; (2,5 mm²)

Driftsforhold

Omgivelsestemperatur [°C] -30,00...100,00

Mekaniske data

Vekt [g] 41,70

Materialer strømbelastningsdeler: kopplerlegering fortinnet; PA

Tiltrekkingmoment [Nm] 0,50

Merknader

Antall i forpakning 6,00 stk.

Elektrisk tilkobling

0,2...2,5 mm²; Abisolierlänge: 7 mm