





Y tilkoblingskabel

Cable/Plug&Play/M12/0.6m

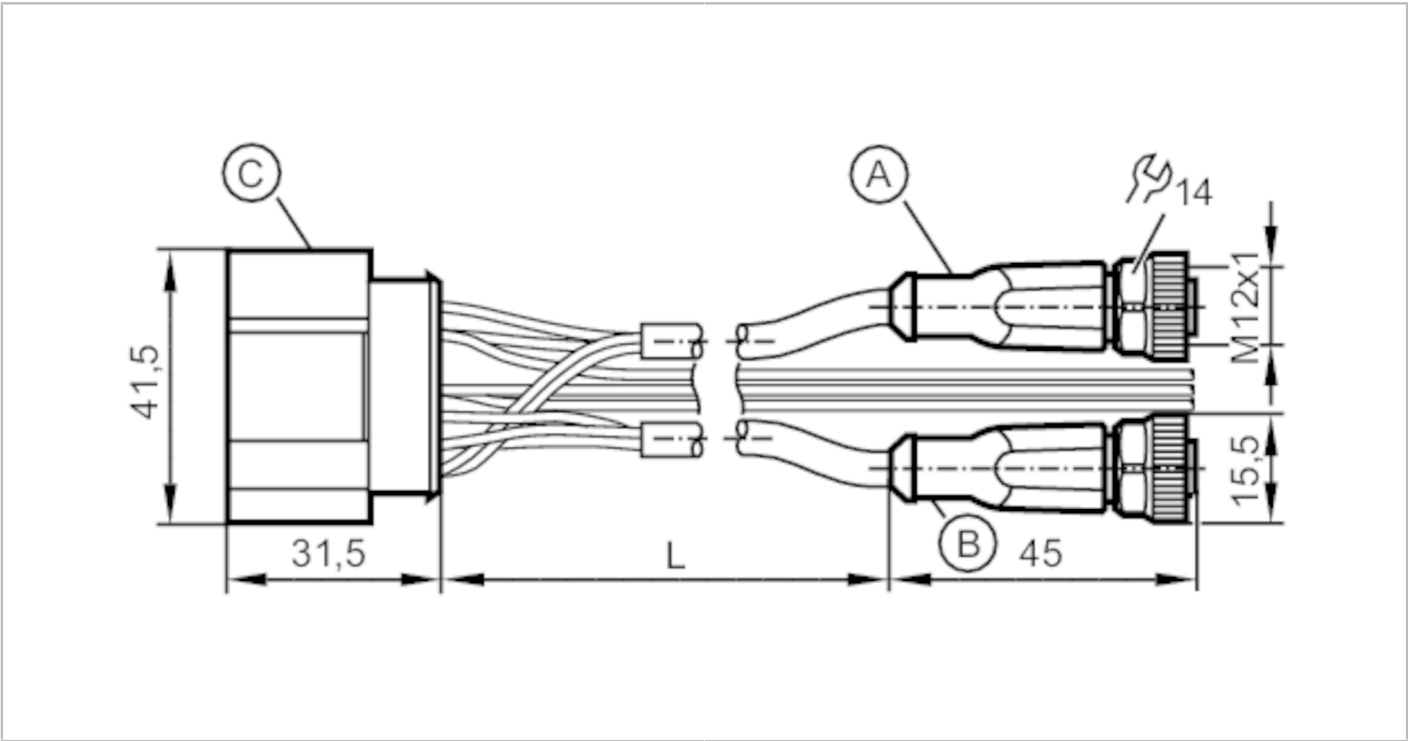

Applikasjon	
Design	Adapterkabel
Elektriske data	
Driftsspenning [V]	8,00...32,00 DC
Driftsforhold	
Omgivelsestemperatur [°C]	-20,00...85,00
Mekaniske data	
Vekt [g]	109,00
Materialer	hus: PBT svart; Stikkontakter: TPU oransje; Forsegling: Viton
Merknader	
Antall i forpakning	1,00 stk.
Elektrisk tilkobling - C	

Koblinger: 1 x AMP-kontakt, rett

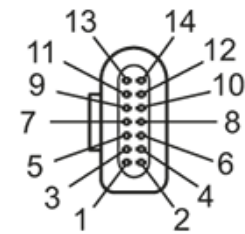


Elektrisk tilkobling	
Kabel: 0,6 m, PUR, svart, Ø 5,1 mm; 5 x 0,5 mm²	
Kabel: 0,6 m, PUR, svart, Ø 4,9 mm; 3 x 0,5 mm²	

Y tilkoblingskabel

Cable/Plug&Play/M12/0.6m


Kabel: 0,6 m; 2 x 0,5 mm²

Tilkobling

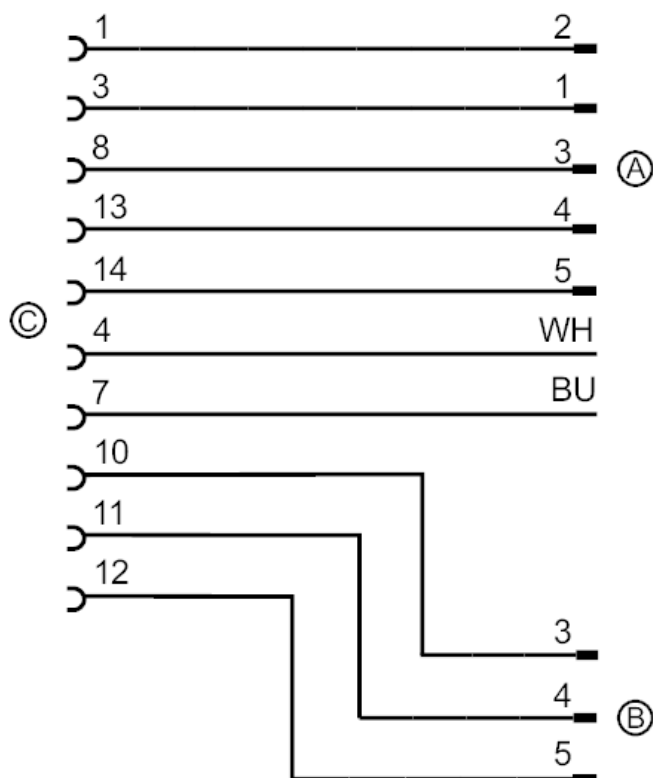

Elektrisk tilkobling - A

Koblinger: 1 x M12, rett; koding: A; låse: messing, forniklet; Tiltrekkingsmoment: 0,6...1,5 Nm

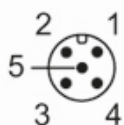

Elektrisk tilkobling - B

Koblinger: 1 x M12, rett; koding: A; låse: messing, forniklet; Tiltrekkingsmoment: 0,6...1,5 Nm

