


Fellesantenne for navigasjon og radio

LTE/GNSS/FAKRA-Antenna

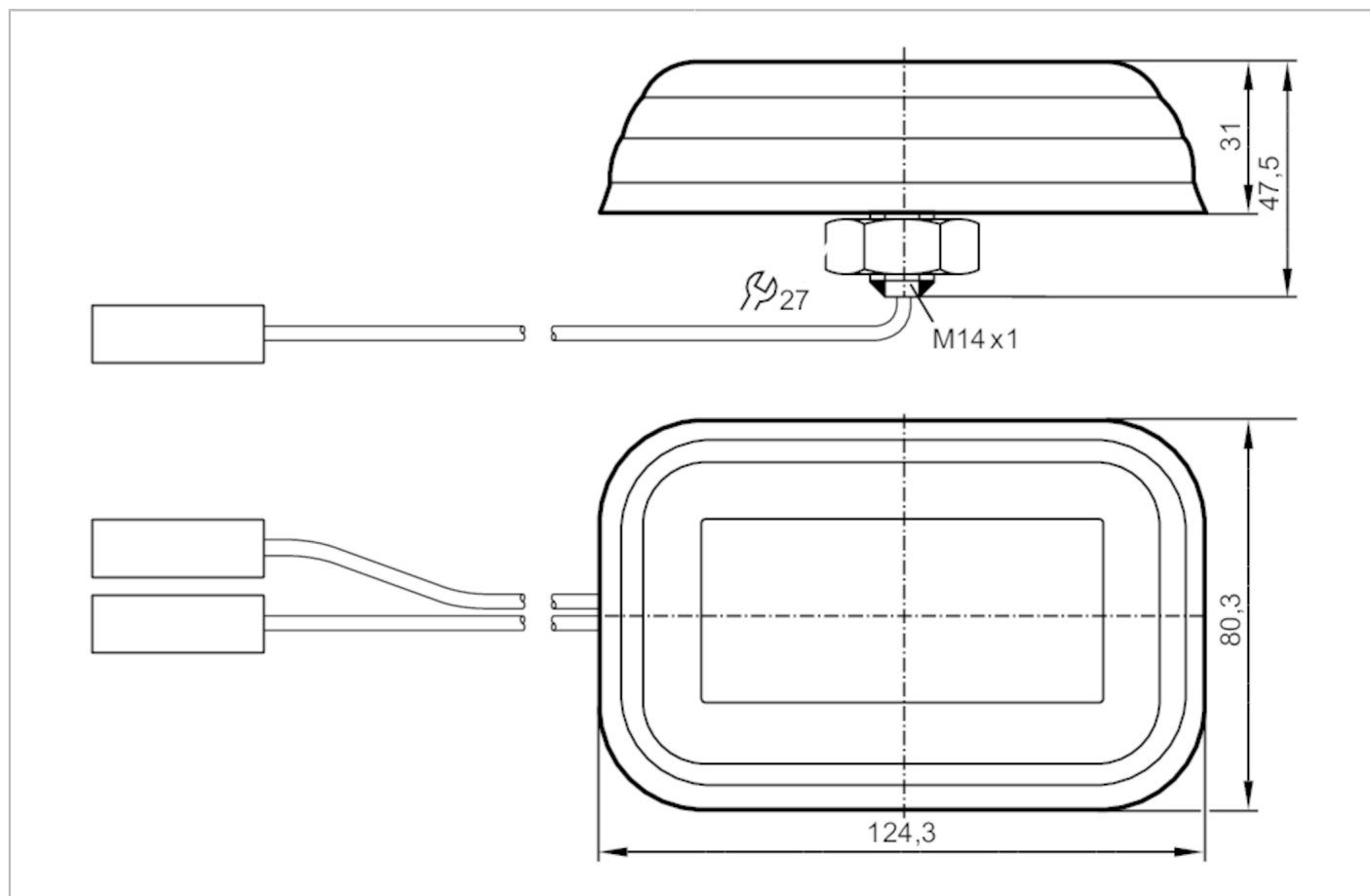

Elektriske data

Strømforbruk	[mA]	< 24,00
--------------	------	---------

Grensesnitt

GNSS

Frekvensbånd	GPS: 1563...1587 MHz (L1); Galileo: 1559...1591 MHz (E1); Beidou: 1559...1591 MHz (B1C); GLONASS: 1593...1610 MHz (G1)
--------------	---

Merknad om grensesnitt

Driftsspenning: 3...5,5 V DC

Impedans: 50 Ohm

Polarisasjon: RHCP

vertikal

LNA: 27 ± 1 dB

Rauschzahl: 2.2 dB

Mobilnettverk

Frekvensbånd	698 ...960 MHz; 710...2170 MHz; 2300...2690 MHz
--------------	---

Merknad om grensesnitt

Impedans: 50 Ohm

Polarisasjon: lineær vertikal

Driftsforhold

Omgivelsestemperatur	[°C]	-40,00...85,00
----------------------	------	----------------

Beskyttelse	IP 6K6
-------------	--------

Mekaniske data

Vekt	[g]	366,00
------	-----	--------

Type montering	Gewinde
----------------	---------

EC3158



Fellesantenne for navigasjon og radio

LTE/GNSS/FAKRA-Antenna

Dimensjoner	[mm]	80,00 x 124,00 x 31,00
Materialer		PC svart
Tiltrekkingsmoment	[Nm]	< 5,00

Merknader

Antall i forpakning	1,00 stk.
---------------------	-----------

Elektrisk tilkobling - GPS

Kabel: 3 m
Koblinger: 1 x FAKRA

Elektrisk tilkobling - GSM

Kabel: 3 m
Koblinger: 1 x FAKRA