


MKT3028BBPKG/G/0,1M/ZH/AS



CE cUL US LISTED UK CA

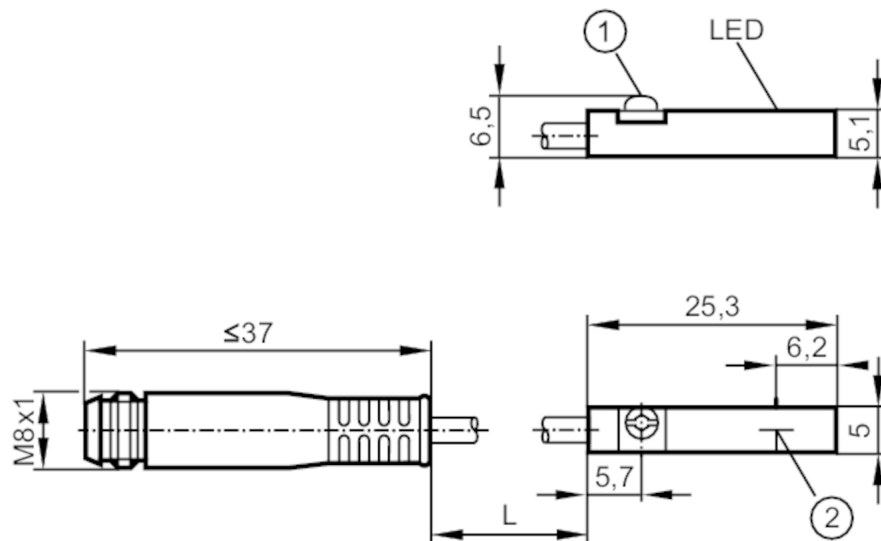

T-spor sylinder sensor

MKT3028BBPKG/G/0,1M/ZH/AS

Repetérbarhet	[mm]	< 0,20
---------------	------	--------

Driftsforhold

Omgivelsestemperatur	[°C]	-25,00...85,00
----------------------	------	----------------

Beskyttelse	IP 65; IP 67
-------------	--------------

Tester/godkjenninger

EMC	EN 61000-4-2 ESD	- CD / 8 kV AD
	EN 61000-4-3 HF utstrålt	10 V/m
	EN 61000-4-4 Burst	2 kV
	EN 61000-4-6 HF ledet	10 V
	EN 55011	klasse B

MTTF	[ANN]	3 694,00
------	-------	----------

UL godkjenning	UL Godkjenning nr.	C003
----------------	--------------------	------

Mekaniske data

Vekt	[g]	9,90
------	-----	------

Montering	kan monteres innfelt
-----------	----------------------

Type montering	festeklemme med kombinert spor / sekskantfatning, bredde over flater 1,5
----------------	--

Sylindertyper	T-spor sylindere
---------------	------------------

Dimensjoner	[mm]	25,00 x 5,00 x 6,50
-------------	------	---------------------

Materialer	hus: PA; festeklemme: rustfritt stål:
------------	---------------------------------------

Displayer/driftselementer

Display	koblingsstatus	1 x LED, gul
---------	----------------	--------------

Tilbehør

Varer som leveres	gummi plassholder: 1
-------------------	----------------------

	Kabelklemme: 1
--	----------------

Merknader

Antall i forpakning	1,00 stk.
---------------------	-----------

Elektrisk tilkobling - koble

Kabel: 0,1 m, PUR

Koblinger: 1 x M8; koding: A; låse: snap-fit
--



MK5129



T-spor sylinder sensor

MKT3028BBPKG/G/0,1M/ZH/AS

Tilkobling

