


Connecting cable with socket

ADOAH040MSS0010A04

Article no longer available - archive entry

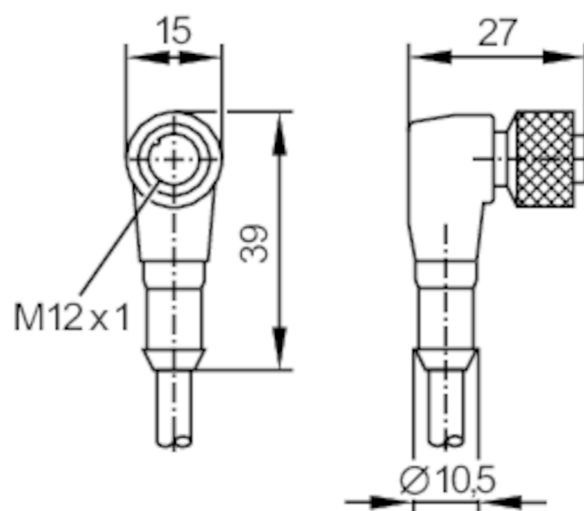

Electrical data

Operating voltage	[V]	< 250 AC / < 300 DC
-------------------	-----	---------------------

Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 67

Mechanical data

Dimensions	[mm]	27 x 15 x 39
Materials		TPU
Moulded-body material		TPU
Material nut		brass, nickel-plated

Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection

Cable: 10 m, PUR / PVC, orange, Ø 5 mm; 4 x 0.25 mm²

Electrical connection - socket

Connector: 1 x M12, angled; coding: A; Moulded body: TPU; Locking: brass, nickel-plated; Tightening torque: 0.5 Nm



E10454



Connecting cable with socket

ADOAH040MSS0010A04

Connection



BN =	Core colours :	brown
BK =		black
BU =		blue
WH =		white