


E10525



Connecting cable with socket

ADOGH040MSS0005F03

Article no longer available - archive entry

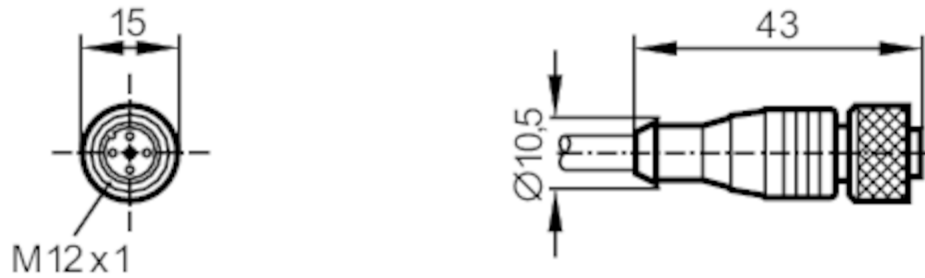

Electrical data

Operating voltage [V] < 250 AC / < 300 DC

Operating conditions

Ambient temperature [°C] -25...90

Protection IP 67

Mechanical data

Dimensions [mm] 15 x 15 x 43

Materials TPU

Moulded-body material TPU

Material nut brass, anti-spatter

Remarks

 
Pack quantity 1 pcs.

Electrical connection

Cable: 5 m, PVC, orange, Ø 5 mm; cross-linked; 3 x 0.34 mm²

Electrical connection - socket

Connector: 1 x M12, straight; Moulded body: TPU; Locking: brass, anti-spatter




E10525



Connecting cable with socket

ADOGH040MSS0005F03

Connection

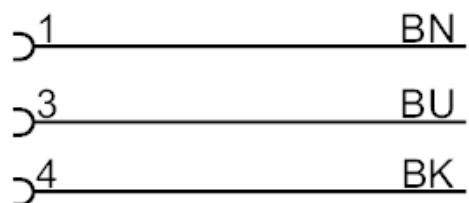

Core colours :

BN = brown
BK = black
BU = blue