




Connection cable

VDOAH042MSS0002B03STGH040MSS

Article no longer available - archive entry

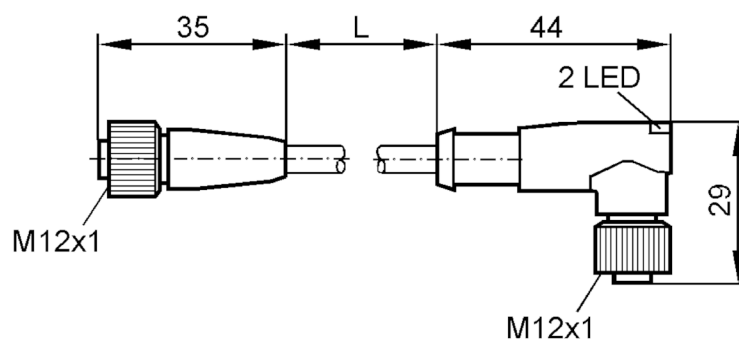

Electrical data

Operating voltage	[V]	10...30 DC
-------------------	-----	------------

Outputs

Electrical design	PNP
-------------------	-----

Operating conditions

Ambient temperature	[°C]	-20...70
---------------------	------	----------

Protection	IP 67
------------	-------

Mechanical data

Materials	PA 6.6
-----------	--------

Moulded-body material	PA 6.6
-----------------------	--------

Material nut	aluminium, black anodised
--------------	---------------------------

Displays / operating elements

Display	switching status	1 x LED, yellow
	operation	1 x LED, green

Remarks

Pack quantity	1 pcs.
---------------	--------

E10568



Connection cable

VDOAH042MSS0002B03STGH040MSS

Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: PA 6.6; Locking: aluminium, black anodised



Electrical connection

Cable: 2 m, PUR, orange; cross-linked; 3 x 0.34 mm²

Connection



Electrical connection - socket

Connector: 1 x M12, angled; coding: A; Moulded body: PA 6.6; Locking: aluminium, black anodised

