




Connecting cable with socket

ADOAH042VAS07,5E03

Article no longer available - archive entry

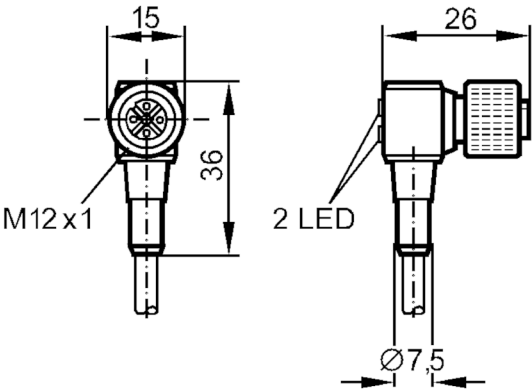

Electrical data

Operating voltage	[V]	10...30 DC
-------------------	-----	------------

Outputs

Electrical design	PNP
-------------------	-----

Operating conditions

Ambient temperature	[°C]	-25...90
---------------------	------	----------

Protection	IP 67
------------	-------

Mechanical data

Materials	PUR
-----------	-----

Moulded-body material	PUR
-----------------------	-----

Material nut	stainless steel (1.4305 / 303)
--------------	--------------------------------

Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection

Cable: 7.5 m, PVC, black, Ø 4.5 mm; 3 x 0.34 mm²

Electrical connection - socket

Connector: 1 x M12, angled; coding: A; Moulded body: PUR; Locking: stainless steel (1.4305 / 303)



E10591



Connecting cable with socket

ADOAH042VAS07,5E03

Connection



	Core colours :
BK =	black
BN =	brown
BU =	blue