

# E10863




## Connecting cable with socket

ADOAF040MSS0002A04

Article no longer available - archive entry

Alternative articles: E11199

When selecting an alternative article and accessories please note that technical data may differ!

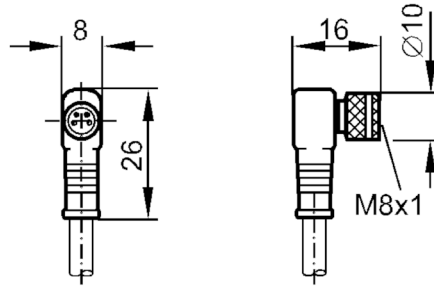

### Electrical data

Operating voltage [V]	< 60 AC / < 75 DC
Protection class	III

### Operating conditions

Ambient temperature [°C]	-25...90
Protection	IP 67; (if screwed on)

### Mechanical data

Dimensions [mm]	16 x 8 x 26
Materials	TPU
Moulded-body material	TPU
Material nut	brass, nickel-plated

### Remarks

 
Pack quantity	1 pcs.
---------------	--------

### Electrical connection

Cable: 2 m, PUR / PVC, orange, Ø 5 mm; 4 x 0.25 mm<sup>2</sup> (32 x Ø 0.1 mm )

### Electrical connection - socket

Connector: 1 x M8, angled; Moulded body: TPU; Locking: brass, nickel-plated




# E10863



## Connecting cable with socket

ADOAF040MSS0002A04

### Connection

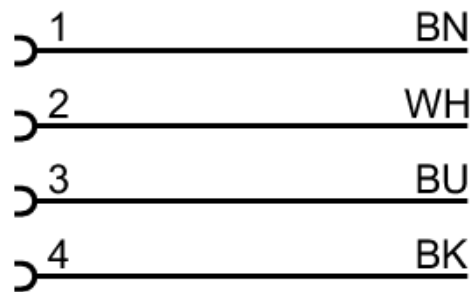

Core colours :

BK =	black
BN =	brown
BU =	blue
WH =	white