


# E10916



## Connecting cable with socket

ADOGH040SCS0005I04

Article no longer available - archive entry

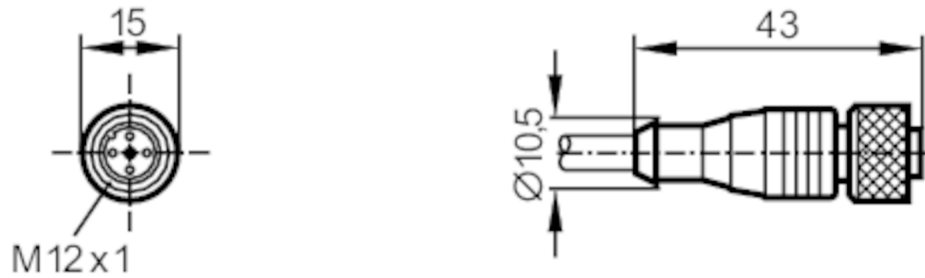

### Application

Special feature	Free from silicone; Halogen-free; Gold-plated contacts
Free from silicone	yes

### Electrical data

Operating voltage	[V]	< 250 AC / < 300 DC
Max. current load total	[A]	4

### Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 68

### Mechanical data

Dimensions	[mm]	15 x 15 x 43
Materials		TPU
Moulded-body material		TPU
Material nut		brass, anti-spatter

### Remarks

Pack quantity	1 pcs.
---------------	--------

### Electrical connection

Cable: 5 m, PUR, Halogen-free, black, Ø 4.8 mm; cross-linked; 4 x 0.34 mm<sup>2</sup>

### Electrical connection - socket

Connector: 1 x M12, straight; Moulded body: TPU; Locking: brass, anti-spatter; Contacts: gold-plated; Tightening torque: 0.5 Nm

# E10916




## Connecting cable with socket

ADOGH040SCS0005I04



### Connection

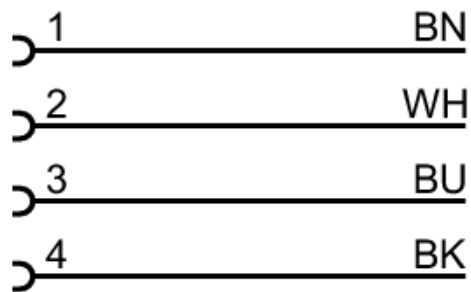

Core colours :

BK =	black
BN =	brown
BU =	blue
WH =	white