


E10958



Connecting cable with socket

ADOAH050SCS0005I05

Article no longer available - archive entry

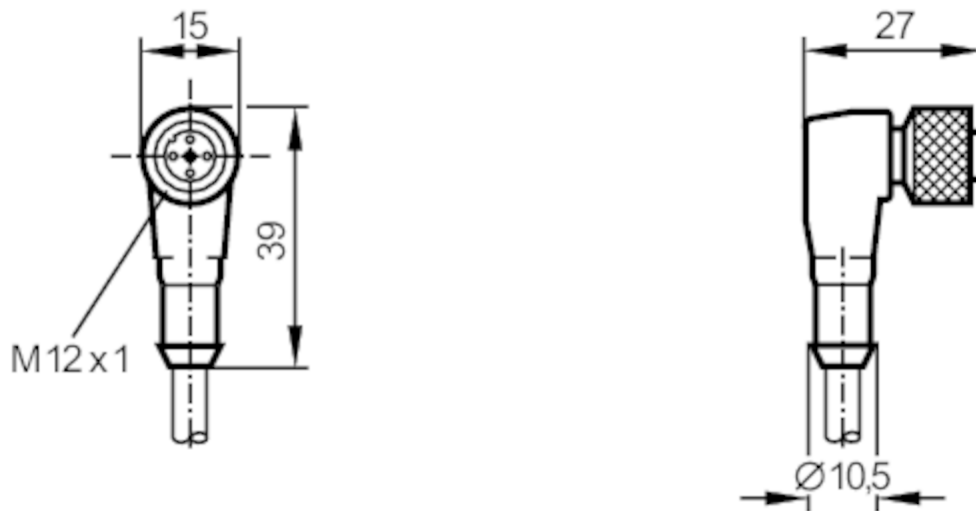


Application	
Special feature	Free from silicone; Halogen-free; Gold-plated contacts
Free from silicone	yes
Electrical data	
Operating voltage [V]	< 30 AC / < 36 DC
Max. current load total [A]	4
Operating conditions	
Ambient temperature [°C]	-25...90
Protection	IP 68
Mechanical data	
Dimensions [mm]	27 x 15 x 39
Materials	TPU
Moulded-body material	TPU
Material nut	brass, anti-spatter
Remarks	
Pack quantity	1 pcs.
Electrical connection	
Cable: 5 m, PUR, Halogen-free, black, Ø 5.5 mm; cross-linked; 5 x 0.34 mm ²	
Electrical connection - socket	
Connector: 1 x M12, angled; Moulded body: TPU; Locking: brass, anti-spatter; Contacts: gold-plated; Tightening torque: 0.5 Nm	

E10958




Connecting cable with socket

ADOAH050SCS0005I05

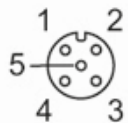

Connection

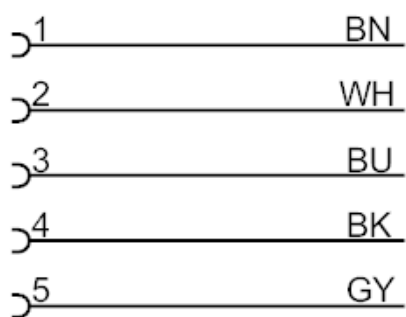

Core colours :

BK =	black
BN =	brown
BU =	blue
GY =	grey
WH =	white