


E10215



Connecting cable with socket

ADOGH040MSS0005A02

Article no longer available - archive entry

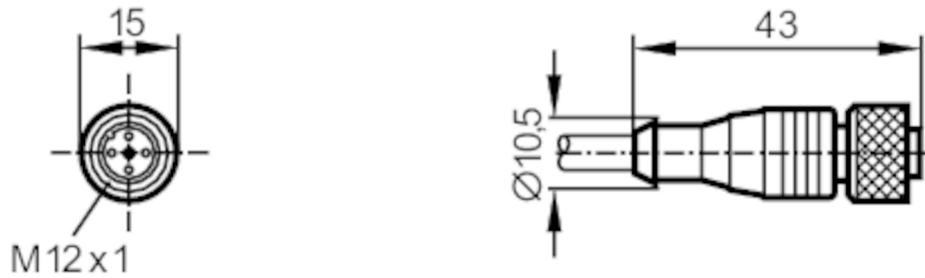

Electrical data

Operating voltage [V] < 250 AC / < 300 DC

Operating conditions

Ambient temperature [°C] -25...90

Protection IP 67

Mechanical data

Dimensions [mm] 15 x 15 x 43

Materials TPU

Moulded-body material TPU

Material nut brass, nickel-plated

Remarks


Pack quantity 1 pcs.

Electrical connection

Cable: 5 m, PUR / PVC, orange, Ø 5 mm; 2 x 0.34 mm²

Electrical connection - socket

Connector: 1 x M12, straight; Moulded body: TPU; Locking: brass, nickel-plated; Tightening torque: 0.5 Nm

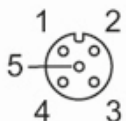


E10215



Connecting cable with socket

ADOGH040MSS0005A02

Connection

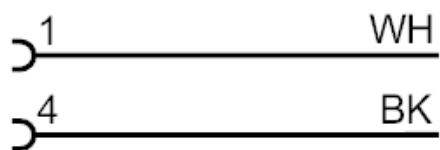

Core colours :

BK = black

WH = white