


E11774



Wirable socket

SDOGH050MSSFKPG

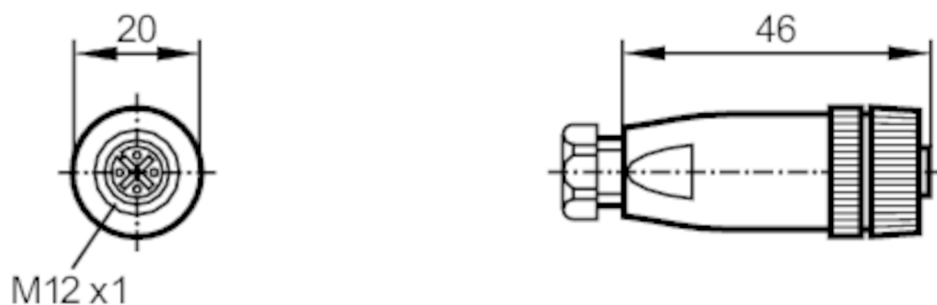

Application

Special feature	Free from silicone; Gold-plated contacts
Free from silicone	yes

Electrical data

Operating voltage	[V]	< 45 AC / < 70 DC
Max. current load total	[A]	4; (...40 °C)

Operating conditions

Ambient temperature	[°C]	-25...100
Protection		IP 68

Mechanical data

Weight	[g]	29.9
Dimensions	[mm]	20 x 20 x 46
Materials		PA
Moulded-body material		PA
Material nut		brass, nickel-plated

Remarks

Pack quantity		1 pcs.
---------------	--	--------

E11774



Wirable socket

SDOGH050MSSFKPG

Electrical connection

screw terminals: ...0.75 mm²; Cable sheath: Ø 6...8 mm

Electrical connection - socket

Connector: 1 x M12, straight; coding: A; Moulded body: PA; Locking: brass, nickel-plated; Contacts: gold-plated



Connection

