


# E11090



## Connecting cable with socket

ADOAF030VAS0010E03

Article no longer available - archive entry

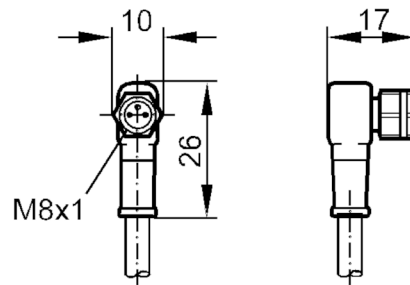

### Electrical data

Operating voltage [V]	< 60 AC / < 75 DC
Protection class	III

### Operating conditions

Ambient temperature [°C]	-25...90
Protection	IP 67

### Mechanical data

Dimensions [mm]	17 x 10 x 26
Materials	TPU
Moulded-body material	TPU
Material nut	stainless steel (1.4305 / 303)

### Remarks

 
Pack quantity	1 pcs.
---------------	--------

### Electrical connection

Cable: 10 m, PVC, orange, Ø 5 mm; 3 x 0.34 mm<sup>2</sup>

### Electrical connection - socket

Connector: 1 x M8, angled; Moulded body: TPU; Locking: stainless steel (1.4305 / 303)




# E11090



## Connecting cable with socket

ADOAF030VAS0010E03

### Connection

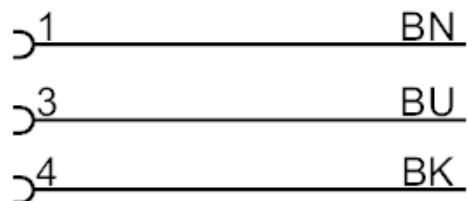

Core colours :

BN =

brown

BK =

black

BU =

blue