

# E11368




## Connection cable

VDOAH040MSS00,3H04STGF040MSS

Article no longer available - archive entry

Alternative articles: EVC285

When selecting an alternative article and accessories please note that technical data may differ!

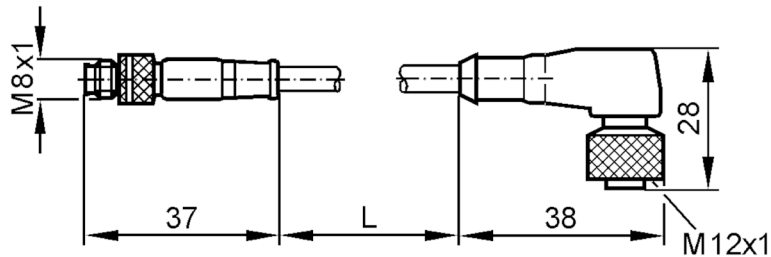

### Application

|                    |  |
|--------------------|--|
| Special feature    | Free from silicone; Halogen-free; Gold-plated contacts |
| Free from silicone | yes  |

### Electrical data

|                         |     |                   |
|-------------------------|-----|-------------------|
| Operating voltage       | [V] | < 60 AC / < 75 DC |
| Protection class        |     | III               |
| Max. current load total | [A] | 3                 |

### Operating conditions

|                     |      |          |
|---------------------|------|----------|
| Ambient temperature | [°C] | -25...85 |
| Protection          |      | IP 68    |

### Mechanical data

|                       |                      |
|-----------------------|----------------------|
| Materials             | PUR                  |
| Moulded-body material | PUR                  |
| Material nut          | brass, nickel-plated |

### Remarks

|               |        |
|---------------|--------|
| Pack quantity | 1 pcs. |
|---------------|--------|

### Electrical connection - plug

Connector: 1 x M8, straight; Moulded body: PUR; Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.6...0.7 Nm

# E11368



## Connection cable


VDOAH040MSS00,3H04STGF040MSS



### Electrical connection

Cable: 0.3 m, PUR, Halogen-free, black,  $\varnothing$  5 mm; 4 x 0.25 mm<sup>2</sup> (32 x  $\varnothing$  0.1 mm )

### Connection

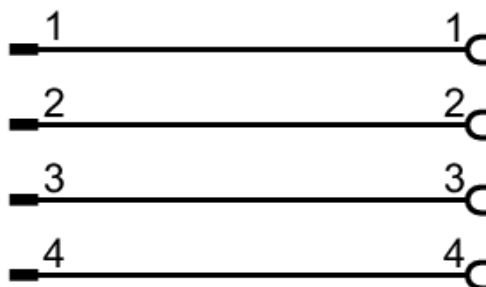

### Electrical connection - socket

Connector: 1 x M12, angled; Moulded body: PUR; Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.7...0.9 Nm

