

E11386




Connection cable

VDOAF032MSS00,3H03STGH030MSS

Article no longer available - archive entry

Alternative articles: EVC225
When selecting an alternative article and accessories please note that technical data may differ!

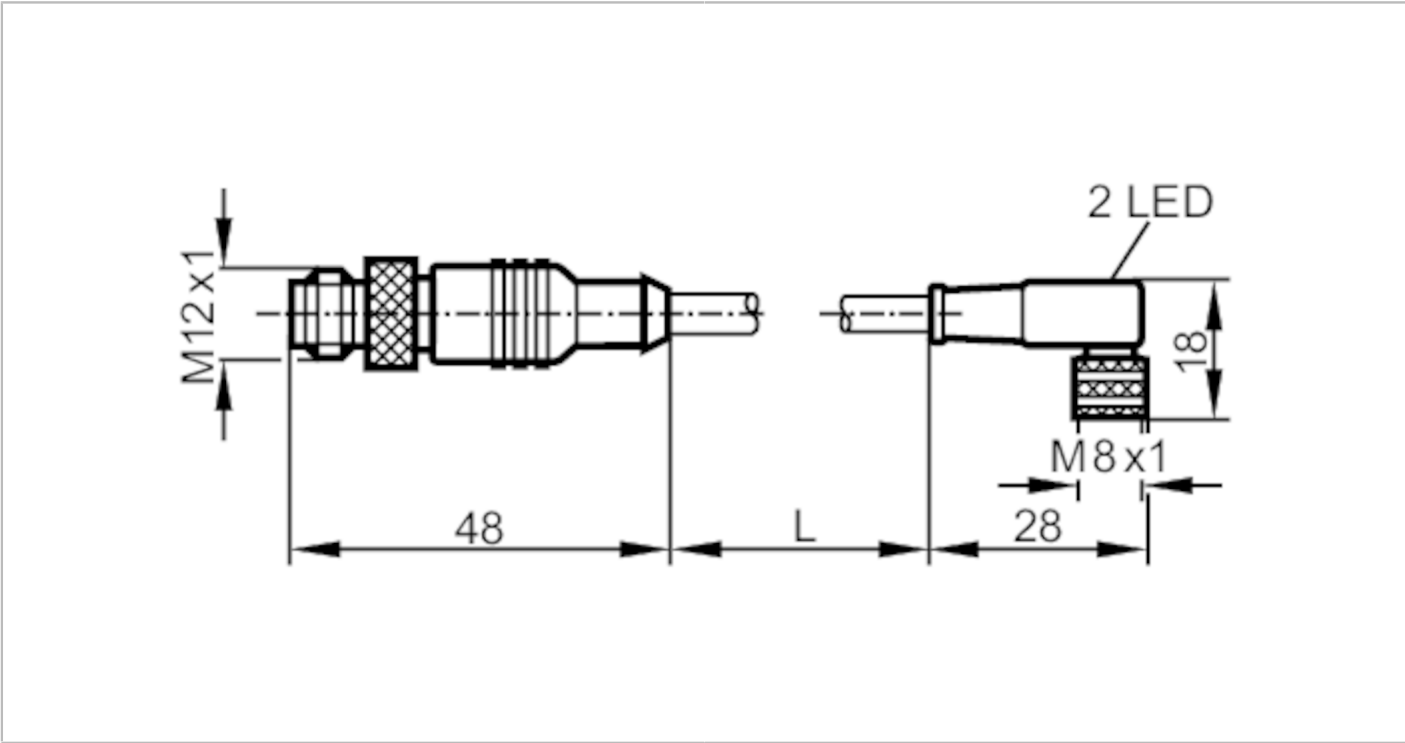

Application		
Special feature	Free from silicone; Halogen-free; Gold-plated contacts	
Free from silicone	yes	
Electrical data		
Operating voltage	[V]	10...30 DC
Protection class		III
Max. current load total	[A]	3
Outputs		
Electrical design	PNP	
Operating conditions		
Ambient temperature	[°C]	-25...85
Protection		IP 68
Mechanical data		
Materials	PUR	
Moulded-body material	PUR	
Material nut	brass, nickel-plated	
Displays / operating elements		
Display	switching status	1 x LED, yellow
	operation	1 x LED, green

E11386



Connection cable

VDOAF032MSS00,3H03STGH030MSS

Remarks

Pack quantity

1 pcs.

Electrical connection - plug


Connector: 1 x M12, straight; coding: A; Moulded body: PUR; Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.7...0.9 Nm



Electrical connection

Cable: 0.3 m, PUR, Halogen-free, black, Ø 4.1 mm; 3 x 0.25 mm² (32 x Ø 0.1 mm)

Connection

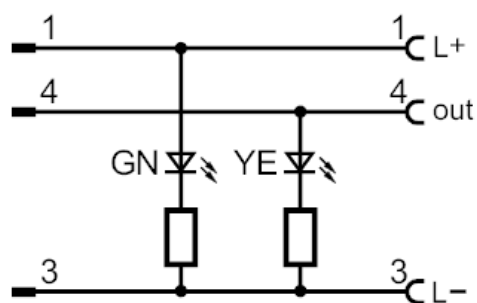

Electrical connection - Buchse




E11386



Connection cable

VDOAF032MSS00,3H03STGH030MSS

Connection

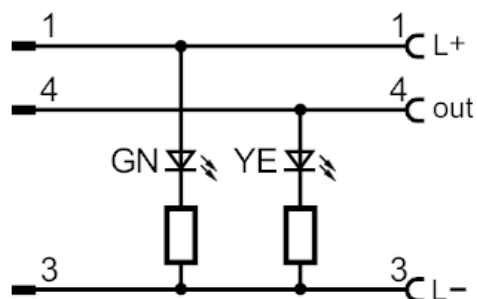

Electrical connection - socket

Connector: 1 x M8, angled; Moulded body: PUR; Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.6...0.7 Nm