


E12535



Connection cable

VDOGH040MSS0007H04STGH04MSS

customer-specific

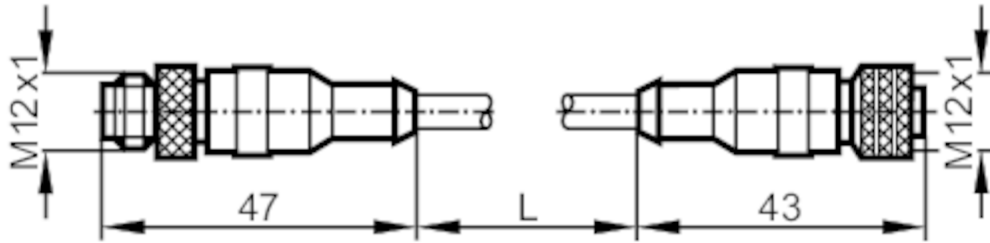

Application

Special feature	Drag chain suitability
Application	microbe-resistant
Oil resistant	yes
UV resistant	yes

Electrical data

Operating voltage [V]	< 250 AC / < 300 DC
Protection class	II
Max. current load total [A]	4

Operating conditions

Ambient temperature [°C]	-40...90
Ambient temperature (moving) [°C]	-15...70
Protection	IP 65; IP 67

Mechanical data

Weight [g]	309.5	
Materials	housing: TPE-U black; Sealing: FKM	
Material nut	diecast zinc, nickel-plated	
Drag chain suitability	yes	
Drag chain suitability	bending radius for flexible use	min. 8 x cable diameter
	bending radius for fixed installation	min. 4 x cable diameter

E12535



Connection cable

VDOGH040MSS0007H04STGH04MSS

Remarks

Remarks	resistant to high mechanical stress
Notes	customer-specific
Pack quantity	1 pcs.

Electrical connection - plug


Connector: 1 x M12, straight; Locking: diecast zinc, nickel-plated; Tightening torque: 0.7...0.9 Nm



Electrical connection

Cable: 7 m, PUR, black, \varnothing 5.8 mm; twisted pairs; 2 x 0.34 mm² (42 x \varnothing 0.1 mm)

Connection

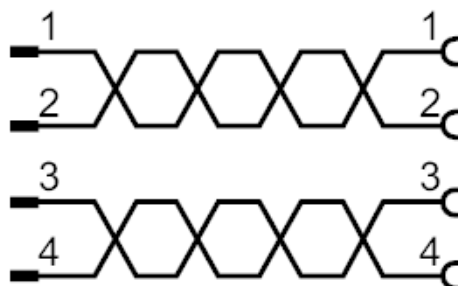

Electrical connection - socket

Connector: 1 x M12, straight; Locking: diecast zinc, nickel-plated; Tightening torque: 0.7...0.9 Nm

