


# E12655



## Connection cable

VDOGX050MSS0005H05STGH005MSS

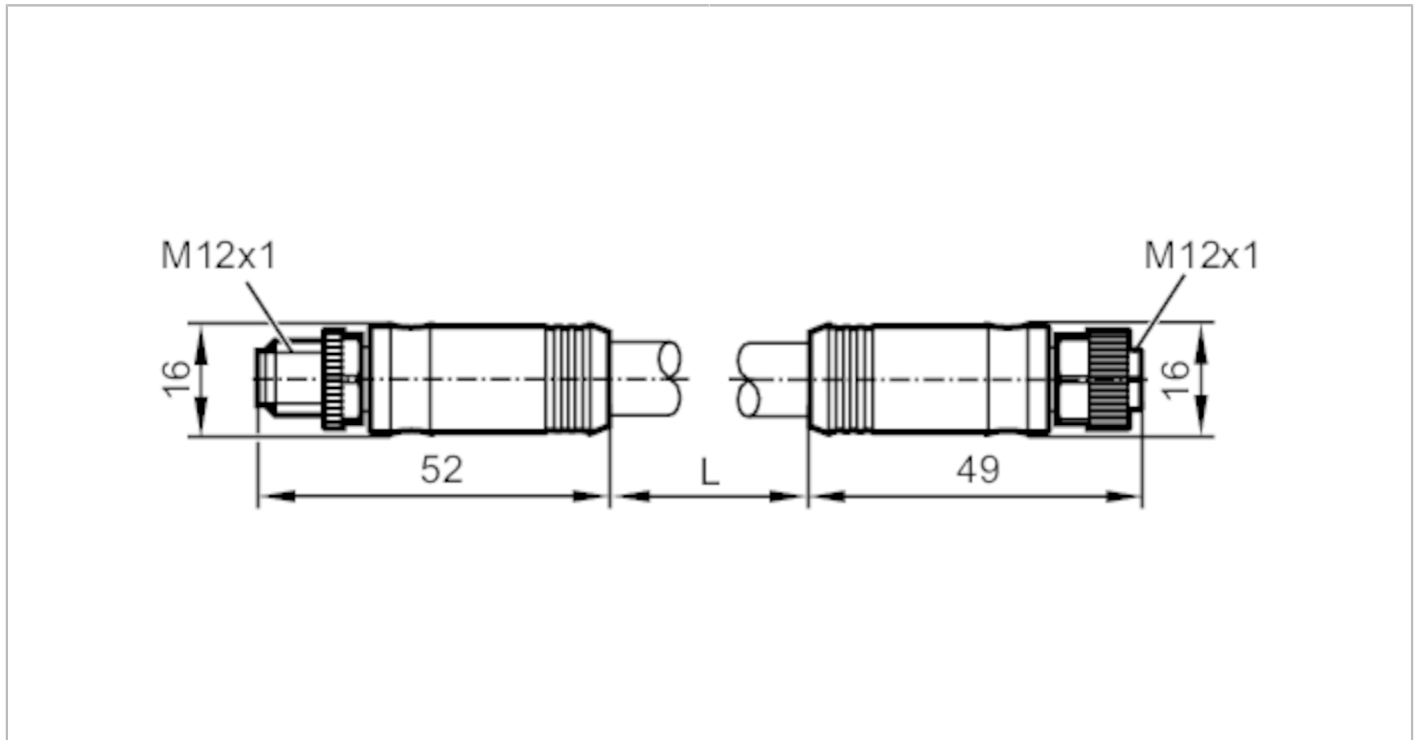

Application		
Special feature		Gold-plated contacts
Design		power cable, L-coded
Electrical data		
Operating voltage	[V]	64 DC
Max. current load total	[A]	16
Operating conditions		
Ambient temperature	[°C]	-40...90
Protection		IP 67
Mechanical data		
Weight	[g]	1119.7
Materials		PP
Material nut		brass, nickel-plated / brass, nickel-plated
Remarks		
Pack quantity		1 pcs.
Electrical connection		
Cable: 5.00 m, PUR, black, Ø 11.3 mm; 5 x 2.5 mm <sup>2</sup>		
Electrical connection - plug		
Connector: 1 x M12, straight; Moulded body: TPE; Locking: brass, nickel-plated; Contacts: gold-plated		

# E12655




## Connection cable

VDOGX050MSS0005H05STGH005MSS



### Electrical connection - 2

#### Connection

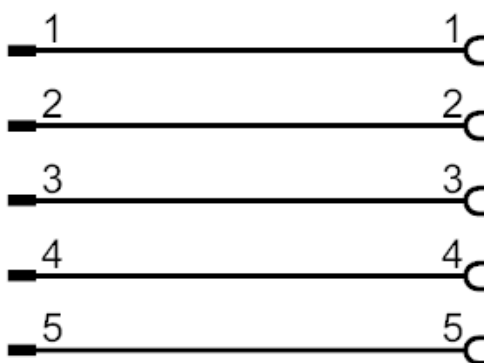

### Electrical connection - socket

Connector: 1 x M12, straight; Moulded body: TPE; Locking: brass, nickel-plated; Contacts: gold-plated

