


# E12266



## Wirable plug

SSTGH040MSSFKPG

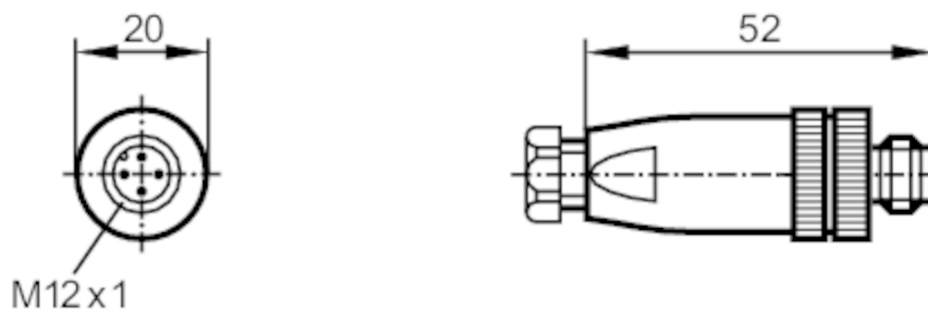

### Application

|                    |                                          |
|--------------------|------------------------------------------|
| Special feature    | Free from silicone; Gold-plated contacts |
| Free from silicone | yes                                      |

### Electrical data

|                         |     |                   |
|-------------------------|-----|-------------------|
| Operating voltage       | [V] | < 45 AC / < 70 DC |
| Max. current load total | [A] | 4; (...40 °C)     |

### Operating conditions

|                     |      |          |
|---------------------|------|----------|
| Ambient temperature | [°C] | -25...85 |
| Protection          |      | IP 68    |

### Mechanical data

|                       |      |                      |
|-----------------------|------|----------------------|
| Weight                | [g]  | 24.9                 |
| Dimensions            | [mm] | 20 x 20 x 52         |
| Materials             |      | PA                   |
| Moulded-body material |      | PA                   |
| Material nut          |      | brass, nickel-plated |

### Remarks

|               |  |        |
|---------------|--|--------|
| Pack quantity |  | 1 pcs. |
|---------------|--|--------|

# E12266



## Wirable plug

SSTGH040MSSFKPG

### Electrical connection

screw terminals: ...0.75 mm<sup>2</sup>; Cable sheath: Ø 2.5...3.5 mm

### Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: PA; Locking: brass, nickel-plated; Contacts: gold-plated



### Connection

