




Adapter plug

RSTGB040ALS00.3-04

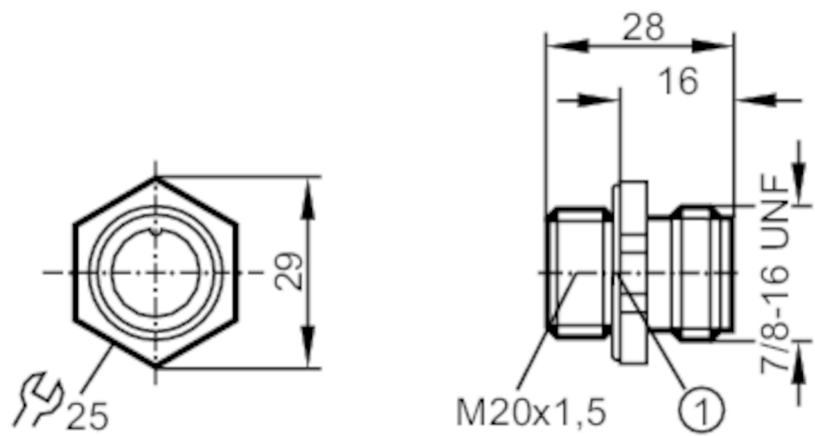

Application	
Special feature	Gold-plated contacts
Electrical data	
Operating voltage	[V] < 600 AC/DC
Operating conditions	
Ambient temperature	[°C] -20...100
Protection	IP 68
Mechanical data	
Weight	[g] 36.287
Mounting thread	M20 x 1,5
Materials	aluminium anodised
Moulded-body material	aluminium, anodised
Remarks	
Pack quantity	1 pcs.

Electrical connection	
, PVC; 4 x 1.5 mm² / AWG 16	

Electrical connection - plug	
------------------------------	--

Connector: 1 x 7/8", straight; coding: A; Moulded body: aluminium, anodised; Contacts: gold-plated



E18071



Adapter plug

RSTGB040ALS00.3-04

Connection

1	BK
2	BU
3	BN
4	WH

	Core colours :
BK =	black
BN =	brown
BU =	blue
WH =	white