


E18247



Connection cable


VDOGA050MSS0.15E04STGA040MSS

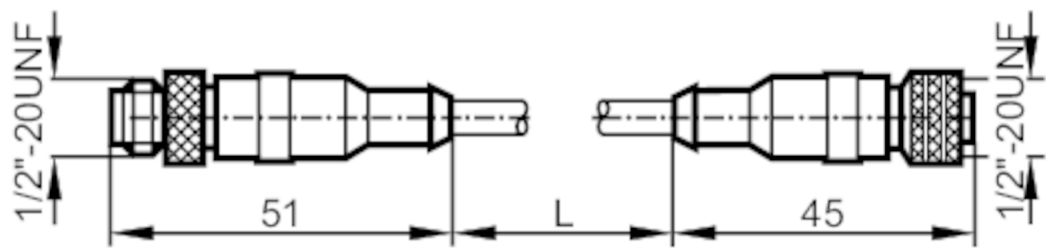

Application		
Special feature		Free from silicone; Halogen-free; Gold-plated contacts
Free from silicone		yes
Electrical data		
Operating voltage	[V]	< 60 AC / < 75 DC
Max. current load total	[A]	3
Operating conditions		
Ambient temperature	[°C]	-25...85
Protection		IP 68
Mechanical data		
Weight	[g]	22.68
Materials		PUR
Moulded-body material		PUR
Material nut		brass, nickel-plated
Remarks		
Pack quantity		1 pcs.

Electrical connection - plug

Connector: 1 x 1/2", straight; coding: C; Moulded body: PUR; Locking: brass, nickel-plated; Contacts: gold-plated

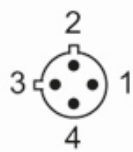

E18247




Connection cable

VDOGA050MSS0.15E04STGA040MSS

Electrical connection

Cable: 0.3 m, PUR, Halogen-free, black, Ø 5 mm; 3 x 0.34 mm² (42 x Ø 0.1 mm)

Connection

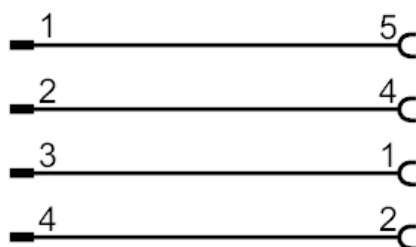

Electrical connection - socket

Connector: 1 x 1/2", straight; coding: C; Moulded body: PUR; Locking: brass, nickel-plated; Contacts: gold-plated

