


Fibre optic through-beam sensor

FE-00-P-A-M4/2M

Article no longer available - archive entry

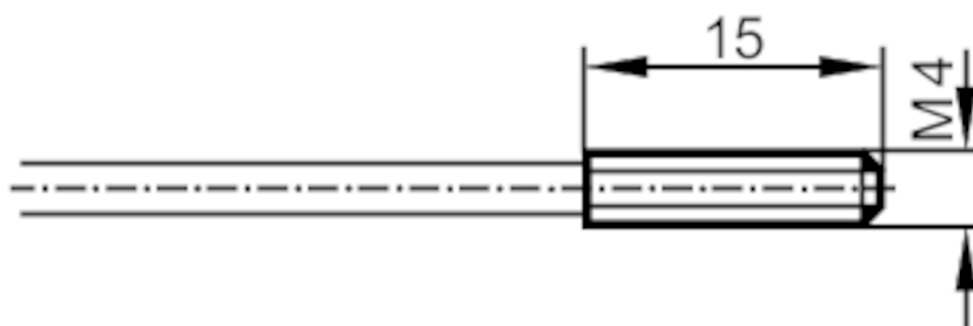

Application

Function principle

Through-beam sensor

Detection zone

Range with fibre-optic
amplifier type

OKF; OUF

OKF

Range of fibre optics

[mm]

96

OUF

Range of fibre optics

[mm]

96

Operating conditions

Ambient temperature

[°C]

-20...80

Mechanical data

Weight

[g]

0.063

Version of sensing head

straight

Sensing head thread

M4

Sensing head length

[mm]

15

Total length

[mm]

2000

Min. bending radius

[mm]

10

Fibre arrangement



E20073



Fibre optic through-beam sensor

FE-00-P-A-M4/2M

Materials	Adapter: PPE
Fibre material	glass
Fibre head material	aluminium
Fibre sheath material	PVC
Accessories	
Items supplied	hexagon nuts: 4 x M4
	tooth lock washers: 4
	knurled nut: 1 x M11
Remarks	
Pack quantity	1 pcs.