


Fibre optic diffuse reflection sensor

FT-00-A-A-M6/1,5M

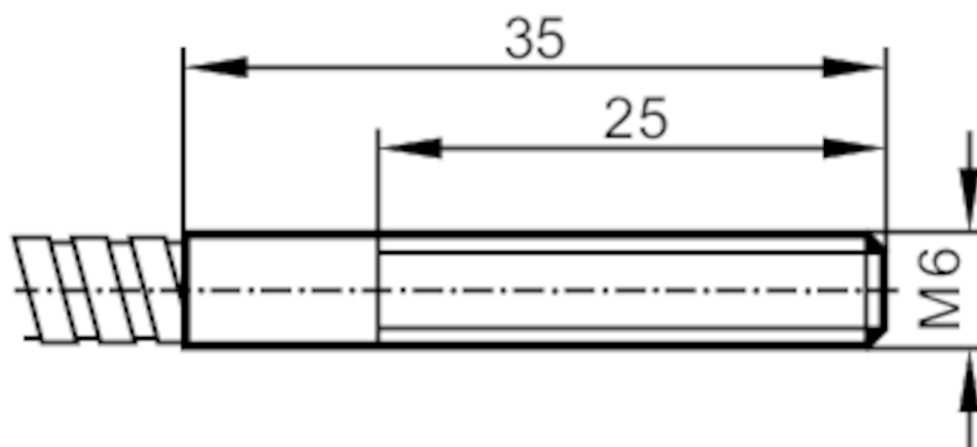

Application

Function principle	Diffuse reflection sensor
Application	High temperature resistance; Robust design for use in harsh industrial environments

Detection zone

Range with fibre optic amplifier type	OCF; OKF; OUF
OCF (High Power)	
Range fibre optics [mm]	270
OKF	
Range fibre optics [mm]	36
OUF	
Range fibre optics [mm]	36

Operating conditions

Ambient temperature [°C]	-40...290
--------------------------	-----------

Mechanical data

Weight [g]	72.5
Version of sensing head	straight
Sensing head thread	M6
Sensing head length [mm]	35
Total length [mm]	1500

E20086



Fibre optic diffuse reflection sensor

FT-00-A-A-M6/1,5M

Min. bending radius	[mm]	20; (for fixed installation)
Fibre arrangement		
Materials		Adapter: ABS
Fibre material		glass
Fibre head material		aluminium
Fibre sheath material		aluminium
Accessories		
Items supplied		hexagon nuts: 2 x M6, stainless steel
		tooth lock washers: 2
		knurled nut: 1 x M11
Remarks		
Pack quantity		1 pcs.