


Fibre optic through-beam sensor

FE-00-A-A-E3/1M

Article no longer available - archive entry

Alternative articles: E20367

When selecting an alternative article and accessories please note that technical data may differ!

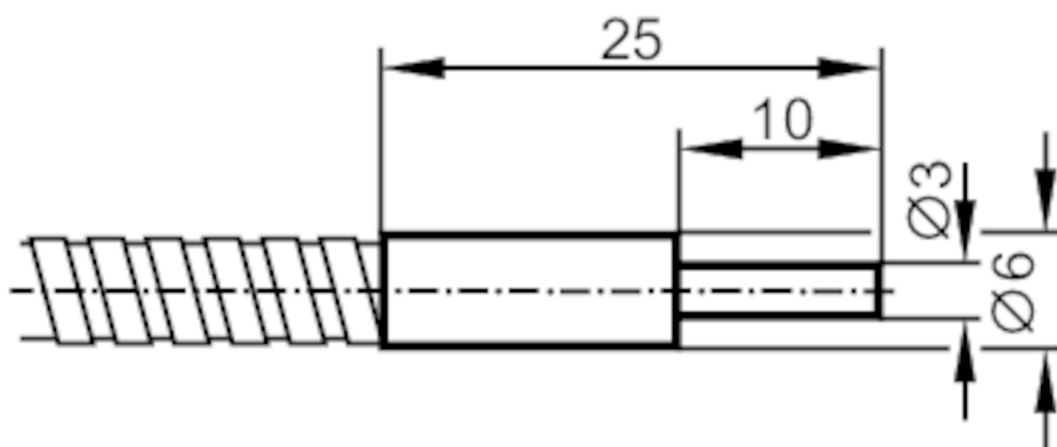

Application

Function principle

Through-beam sensor

Detection zone

Range with fibre-optic amplifier type

OKF; OUF

OKF

Range of fibre optics

[mm]

120

OUF

Range of fibre optics

[mm]

120

Operating conditions

Ambient temperature

[°C]

-40...290

Mechanical data

Version of sensing head

straight

Sensing head diameter

[mm]

3

Sensing head length

[mm]

10

Total length

[mm]

1000

E20141



Fibre optic through-beam sensor

FE-00-A-A-E3/1M

Min. bending radius	[mm]	20
Materials		Adapter: ABS
Fibre material		glass
Fibre head material		aluminium
Fibre sheath material		aluminium
Remarks		
Pack quantity		1 pcs.