

E20311




Fibre optic diffuse reflection sensor

FT-30-A-A-R6/1M

Article no longer available - archive entry

Alternative articles: E20223
When selecting an alternative article and accessories please note that technical data may differ!

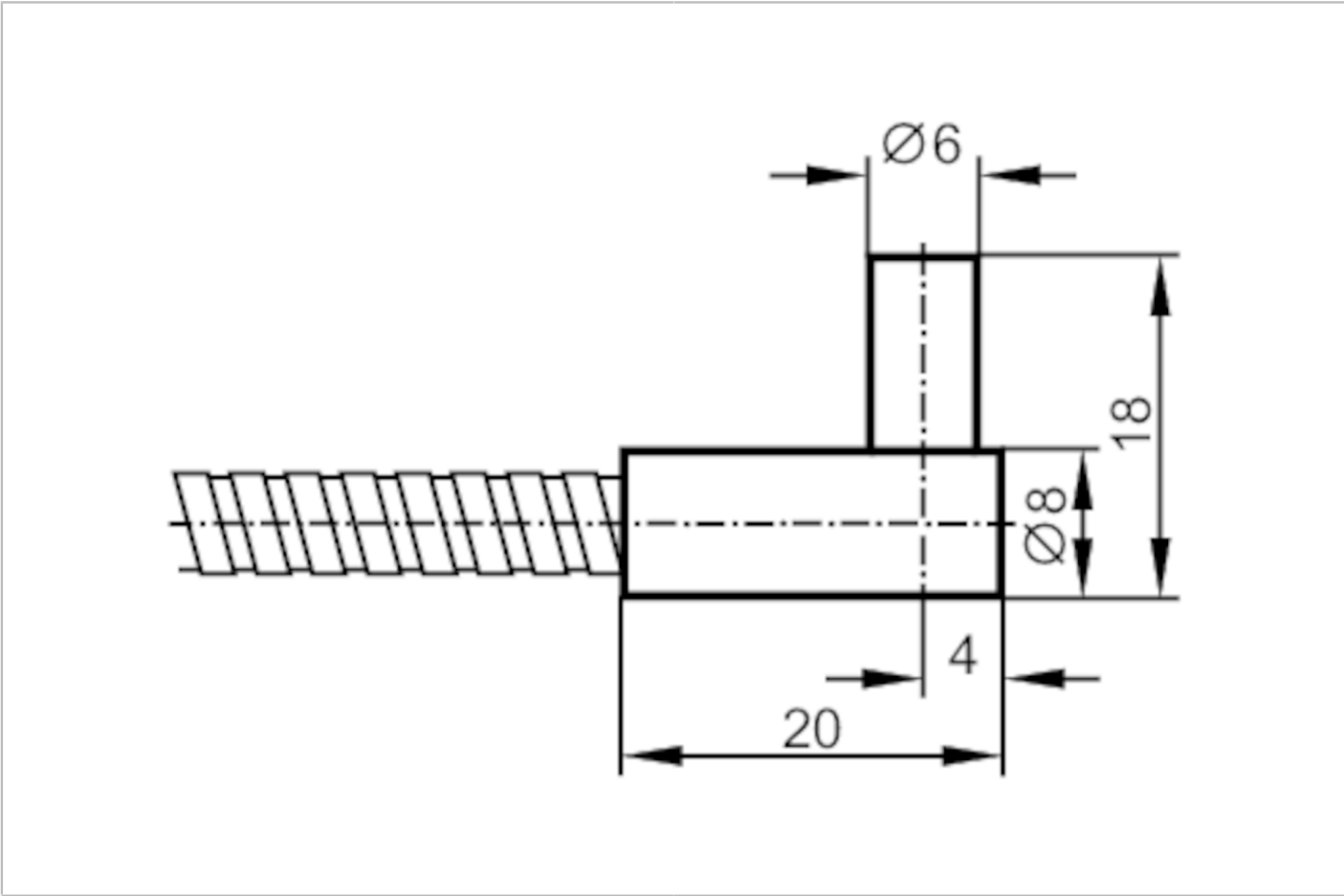

Application	
Function principle	Diffuse reflection sensor
Detection zone	
Range with fibre optic amplifier type	OIF
OIF	
Range fibre optics [mm]	40
Operating conditions	
Ambient temperature [°C]	-40...290
Mechanical data	
Version of sensing head	angled
Total length [mm]	1000
Min. bending radius [mm]	30
Materials	Adapter: PA
Fibre material	glass
Fibre head material	aluminium
Fibre sheath material	aluminium

E20311



Fibre optic diffuse reflection sensor

FT-30-A-A-R6/1M

Remarks	
Pack quantity	1 pcs.