

E33011



Process adapter hygienic pipe fitting


ADAPT IFM-DIN11851/DN32(1.25)

Article no longer available - archive entry

Alternative articles: E33711

When selecting an alternative article and accessories please note that technical data may differ!

The alternative article requires the use of a new sensor with Aseptoflex Vario external thread

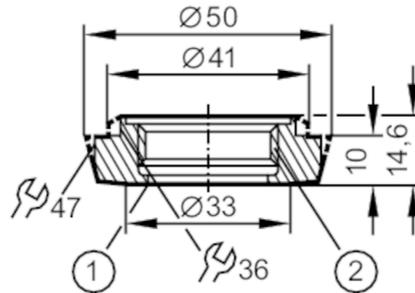

- 1 Aseptoflex sealing edge
- 2 Aseptoflex thread

EC 1935/2004 FCM FDA

Application	
Pressure rating	[bar] 40
Tests / approvals	
Pressure Equipment Directive	A possible classification to PED depends on the application and has to be carried out by the user / operator.
Safety instructions	The compatibility between medium and product material has to be checked in all applications.
Mechanical data	
Weight	[g] 158
Materials	stainless steel (316L/1.4404)
Sensor connection	Aseptoflex
Process connection	hygienic pipe fitting DN32 (1,25") DIN 11851
Surface characteristics Ra/Rz of the wetted parts	0.4 / 4
Hygienic equipment class to DIN 11866	H4
Remarks	
Pack quantity	1 pcs.