


Universal process adapter

ADAPT UNI RD52

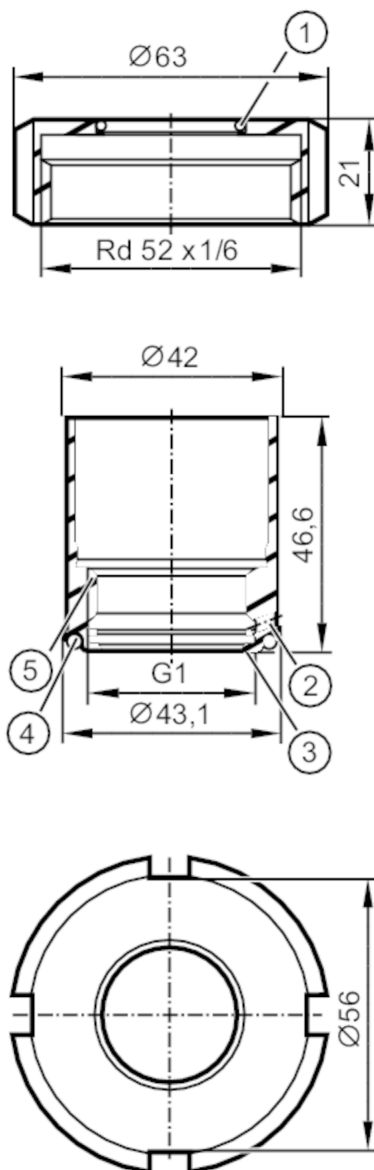

- 1 O-ring 30x2 FKM
- 2 Leakage port
- 3 sealing area for O-ring 24x2
- 4 O-ring 36x3 EPDM
- 5 Aseptoflex Vario



EC 1935/2004 FDA

Application

Design

accessories for, PM17xx: (Endress+Hauser universal process adapter RD52), PY200x: (Endress+Hauser universal process adapter Uni 6" D85)

Pressure rating

[bar]

16

Tests / approvals

Pressure Equipment Directive

A possible classification to PED depends on the application and has to be carried out by the user / operator.



Universal process adapter

ADAPT UNI RD52

Safety instructions	The compatibility between medium and product material has to be checked in all applications.	
Mechanical data		
Weight	[g]	390.1
Materials (wetted parts)	stainless steel (316L/1.4435) ; surface characteristics : Ra<0,4 / Rz 4	
Sensor connection	G 1 Aseptoflex Vario	
Process connection	universal process adapter Rd 52 Endress+Hauser Universal-Prozessadapter RD52; Universal-Prozessadapter Uni 6" D85	
Sealing	Gasket	
Hygienic equipment class to DIN 11866	H4	
Accessories		
Items supplied	O-ring: 24 x 2, EPDM, FDA compliant, E30054	
	O-ring: 30 x 2, FKM	
	O-ring: 36 x 3, EPDM, FDA compliant	
Accessories (optional)	O-ring: 24 x 2, FKM, FDA compliant, E30123	
	sealing ring, PEEK, FDA compliant, E30124	
Remarks		
Pack quantity	1 pcs.	