


E60191



Connecting cable with socket

ADOGK170MSL0020B17

Article no longer available - archive entry

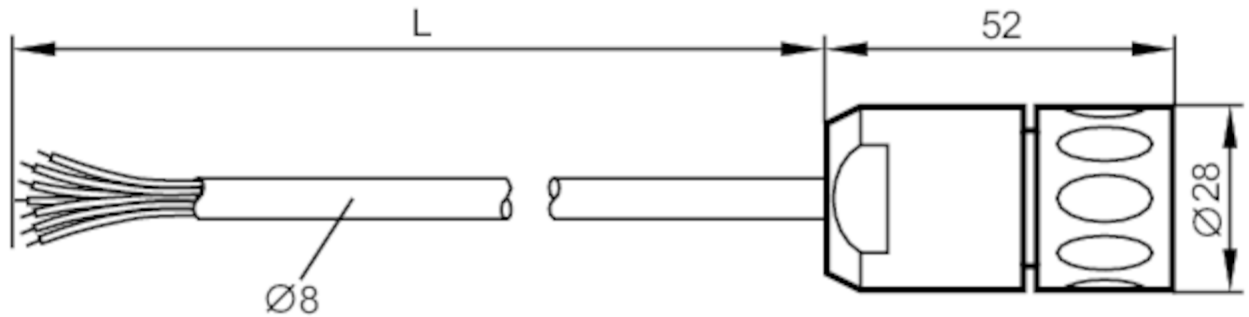

Electrical data

Operating voltage [V] 4.5...30 DC

Operating conditions

Ambient temperature [°C] -10...85

Protection IP 67

Mechanical data

Weight [g] 2000

Dimensions [mm] 28 x 28 x 52

Materials brass in plastic sheath; PA 6.6 black

Moulded-body material brass / PA 6.6, in plastic sheath

Material nut brass, in plastic sheath / PA 6.6, in plastic sheath

Remarks

Pack quantity 1 pcs.

Electrical connection

Cable: 20 m, PUR, Ø 8 mm; 13 x 0.14 mm² + 4 x 0.5 mm²

Electrical connection - socket

Connector: 1 x M23, straight; Moulded body: brass / PA 6.6, in plastic sheath; Locking: brass, in plastic sheath


Connector: 1 x M23, straight; Moulded body: brass / PA 6.6, in plastic sheath; Locking: PA 6.6, in plastic sheath

E60191



Connecting cable with socket

ADOGK170MSL0020B17

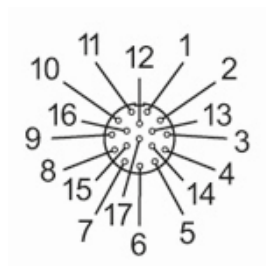

Connection

1	BU
2	BK
3	RD
4	WH
5	GN
6	BN
7	BN/GN
8	VT
9	YE
10	WH/GN
11	screen
12	BU/BK
13	RD/BK
14	GY
15	GN/BK
16	YE/BK
17	PK

Core colours :

BK =	black
BN =	brown
BU =	blue
GN =	green
GY =	grey
PK =	pink
RD =	red
VT =	lilac
WH =	white
YE =	yellow
screen =	screen