

E70090




Jumper cable with valve plug

VVSAB031--S01,5A03STGH030MSS

Article no longer available - archive entry

Alternative articles: E11431

When selecting an alternative article and accessories please note that technical data may differ!

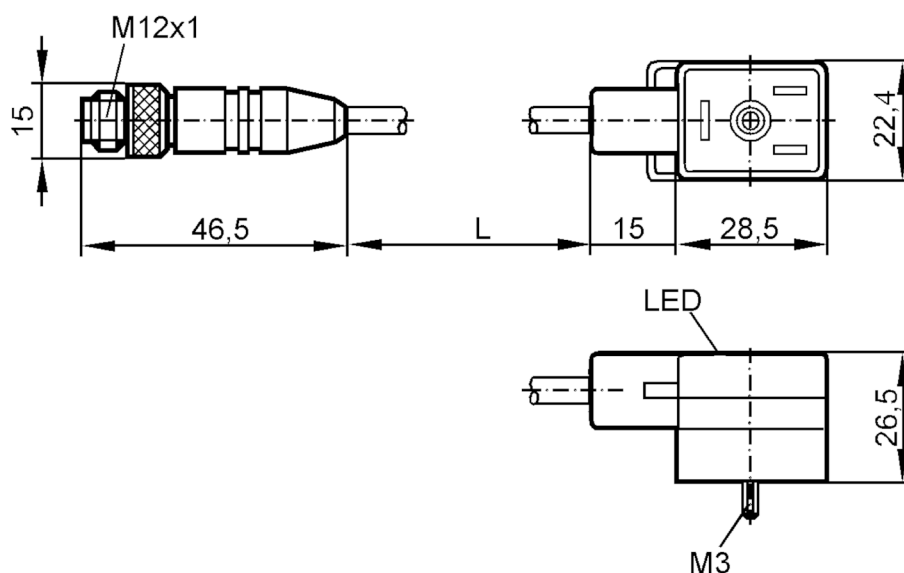

Electrical data

Operating voltage	[V]	< 24 AC/DC
Overtoltage protection		yes; (VDR)

Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 67

Mechanical data

Materials	TPU
Moulded-body material	TPU
Material nut	brass, nickel-plated

Displays / operating elements

Display	switching status	1 x LED, yellow
---------	------------------	-----------------

Accessories

Items supplied	screw
	panel for labelling

Remarks

Pack quantity	1 pcs.
---------------	--------

E70090




Jumper cable with valve plug

VVSAB031--S01,5A03STGH030MSS

Electrical connection - plug

 
Connector: 1 x M12, straight; coding: A; Moulded body: TPU; Locking: brass, nickel-plated



Electrical connection

Cable: 1.5 m, PUR / PVC; 3 x 0.5 mm²

Connection

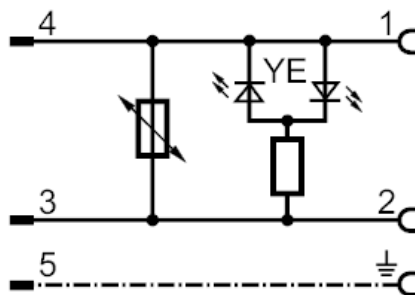

Electrical connection - socket

Connector: 1 x valve type B industrial standard, angled; Moulded body: TPU; Locking: brass, nickel-plated

