


Wirable socket

SDOAL070PLSFKPG

Article no longer available - archive entry

Alternative articles: E11043

When selecting an alternative article and accessories please note that technical data may differ!

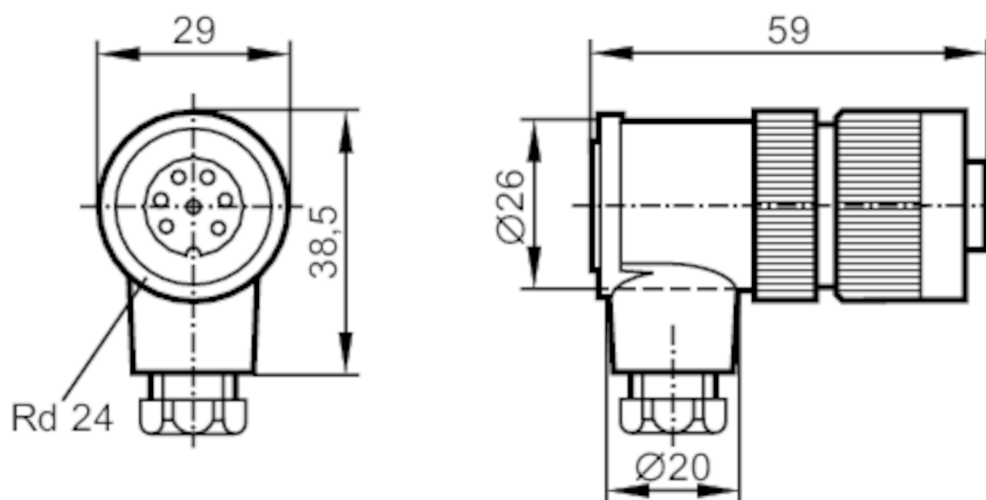

Application

Special feature

Gold-plated contacts

Electrical data

Operating voltage

[V]

< 250 AC / < 300 DC

Operating conditions

Ambient temperature

[°C]

-40...100

Protection

IP 67

Mechanical data

Dimensions

[mm]

59 x 29 x 38.5

Materials

PBT

Moulded-body material

PBT

Material nut

PA

Remarks

Pack quantity

1 pcs.

E70177

 


Wirable socket

SDOAL070PLSFKPG

Electrical connection - socket

Connector: 1 x Rd24, straight; coding: A; Moulded body: PBT; Locking: PA; Contacts: gold-plated



Connection

