


CR0452



Programmable graphic display for controlling mobile machines

R360/BasicDisplay XL

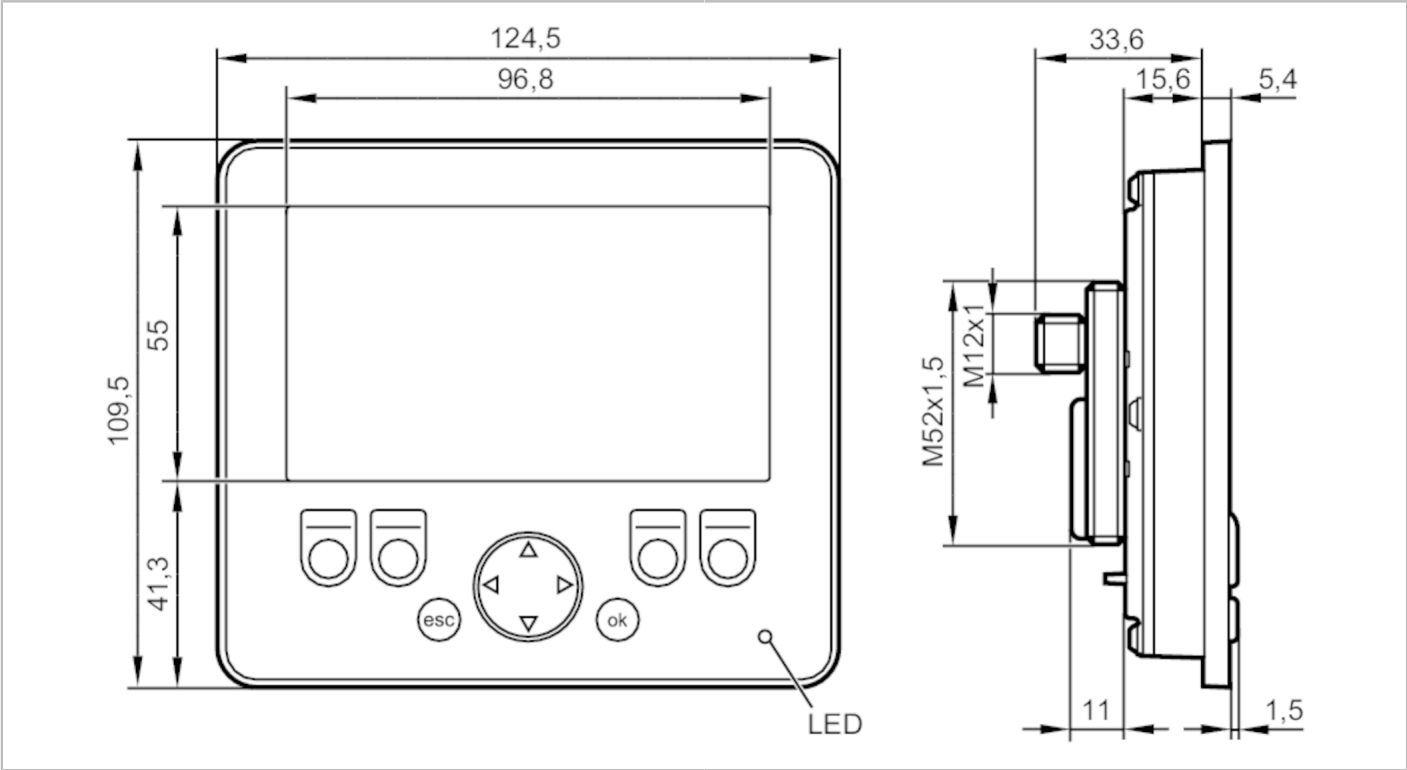

Electrical data		
Operating voltage	[V]	8...32 DC
Software / programming		
PLC function to IEC 61131-3		yes
Interfaces		
Number of CAN interfaces		1
Tests / approvals		
MTTF	[years]	237
Mechanical data		
Weight	[g]	291.5
Type of mounting		panel / surface
Dimensions	[mm]	109.5 x 124.5 x 40.5
Displays / operating elements		
Display		4,3" colour display
Operating elements	6	freely programmable backlit function keys
	1	navigation key for cursor function
Display resolution		480 x 272
Display type		colour display
Display size		4.3"
Display background illumination		LED
Remarks		
Pack quantity		1 pcs.




Programmable graphic display for controlling mobile machines

R360/BasicDisplay XL

Electrical connection

Connector: 1 x M12; coding: A

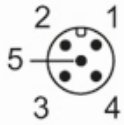

- 1 n.c.
- 2 8...32 V DC
- 3 GND
- 4 CAN_H
- 5 CAN_L