


# E10466



## Connection cable

VDOGH040MSS0002A04STGH040MSS

Article no longer available - archive entry

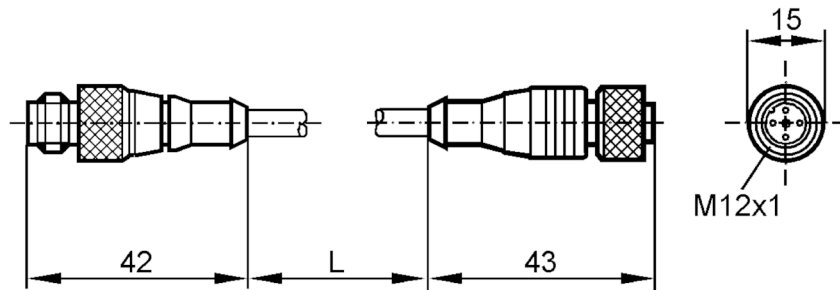

### Electrical data

Operating voltage [V] 10...30 DC

### Operating conditions

Ambient temperature [°C] -25...85

Protection IP 67

### Mechanical data

Dimensions [mm] 15 x 15 x 42

Materials TPU

Material nut brass, nickel-plated / brass, nickel-plated

### Remarks

Pack quantity 1 pcs.

### Electrical connection - plug

Connector: 1 x M12, straight; Moulded body: TPU; Locking: brass, nickel-plated; Tightening torque: 0.5 Nm



# E10466




## Connection cable

VDOGH040MSS0002A04STGH040MSS

### Electrical connection

Cable: 2 m, PUR / PVC; 4 x 0.25 mm<sup>2</sup>

### Connection

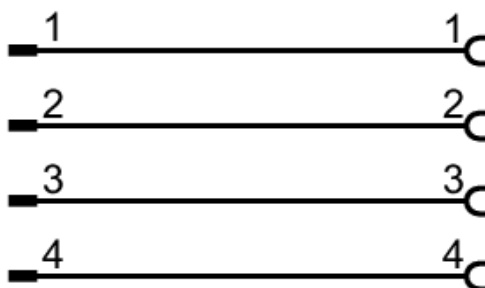

### Electrical connection - socket

Connector: 1 x M12, straight; Moulded body: TPU; Locking: brass, nickel-plated; Tightening torque: 0.5 Nm



Article no longer available - archive entry