




Fibre optic diffuse reflection sensor

FT-00-M-V-E1/1m

Article no longer available - archive entry

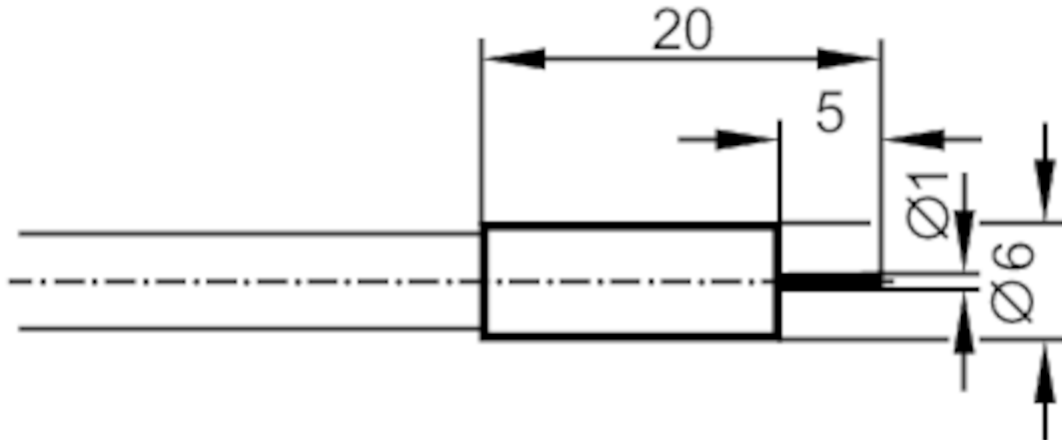

Application

Function principle	Diffuse reflection sensor
--------------------	---------------------------

Detection zone

Range with fibre optic amplifier type	OKF; OUF
---------------------------------------	----------

OKF

Range fibre optics	[mm]	8
--------------------	------	---

OUF

Range fibre optics	[mm]	8
--------------------	------	---

Operating conditions

Ambient temperature	[°C]	-20...150
---------------------	------	-----------

Mechanical data

Version of sensing head	straight
Sensing head diameter [mm]	1
Sensing head length [mm]	5
Total length [mm]	1000
Min. bending radius [mm]	20
Fibre material	glass
Fibre head material	stainless steel (1.4305 / 303)

E20522



Fibre optic diffuse reflection sensor

FT-00-M-V-E1/1m

Fibre sheath material	metal silicone
Remarks	
Pack quantity	1 pcs.