




Fibre optic diffuse reflection sensor

FT-00-A-A-M6/2,6M

Article no longer available - archive entry

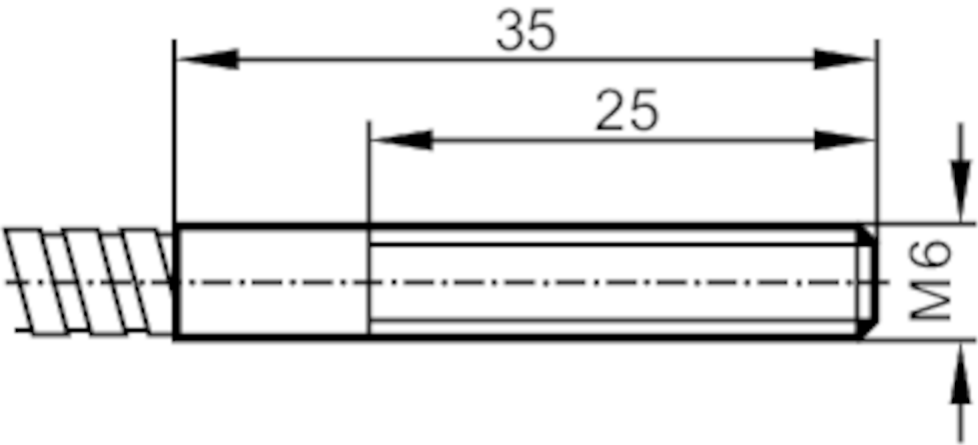

Application		
Function principle		Diffuse reflection sensor
Detection zone		
Range with fibre optic amplifier type		OKF; OUF
OKF		
Range fibre optics	[mm]	28
OUF		
Range fibre optics	[mm]	28
Operating conditions		
Ambient temperature	[°C]	-40...290
Mechanical data		
Version of sensing head		straight
Sensing head thread		M6
Sensing head length	[mm]	35
Total length	[mm]	2600
Min. bending radius	[mm]	20
Materials		Adapter: ABS
Fibre material		glass

E20245



Fibre optic diffuse reflection sensor

FT-00-A-A-M6/2,6M

Fibre head material	aluminium
Fibre sheath material	aluminium
Remarks	
Pack quantity	1 pcs.