


AS-Interface flat cable insulation displacement connector

FC Splitter AS-i M12 FC bottom UL

Alternative articles: E75005

When selecting an alternative article and accessories please note that technical data may differ!

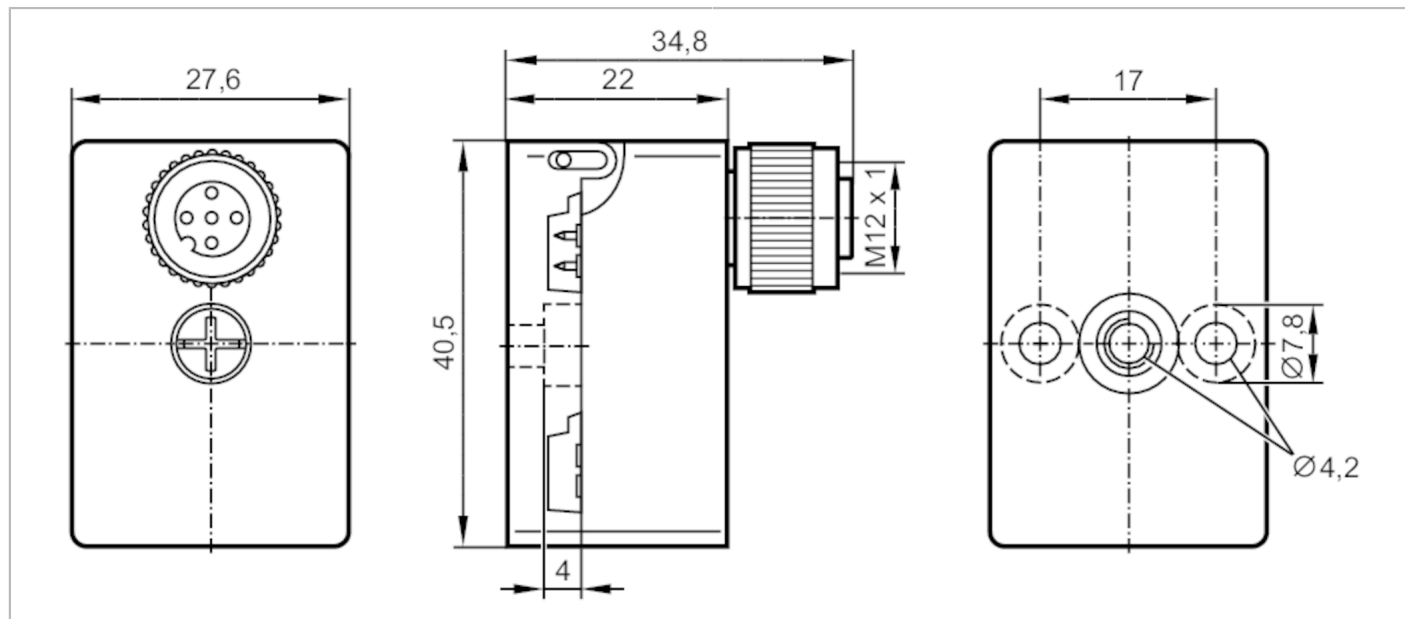

Electrical data

Protection class	III
Max. current load total [A]	4

Outputs

Electrical design	AS-i
-------------------	------

Operating conditions

Ambient temperature [°C]	-25...75
Protection	IP 67

Mechanical data

Weight [g]	54
Materials	PBT / PC
Tightening torque [Nm]	1.65

Accessories

Accessories (optional)	flat cable end seal:, E70413
	heat-shrink cap:, E70113

Remarks

Remarks	The flat cable must not end in the splitter.
	Use a flat cable seal or heat-shrink cap for sealing.
Pack quantity	1 pcs.




AS-Interface flat cable insulation displacement
connector

FC Splitter AS-i M12 FC bottom UL

Electrical connection

Connector: M12; coding: A

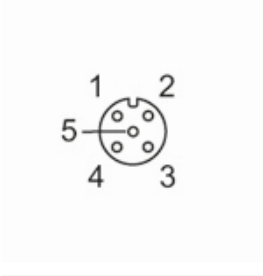

1	AS-i +
3	AS-i -
keyway bottom left	