


E70054



Connection cable

VDOAH040MSS0001A04STAH040MSS

Article no longer available - archive entry

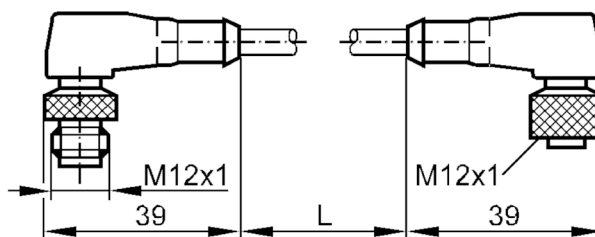

Electrical data

Operating voltage [V] 10...30 DC

Operating conditions

Ambient temperature [°C] -25...90

Protection IP 67

Mechanical data

Materials TPU

Material nut brass, nickel-plated / brass, nickel-plated

Remarks

Pack quantity 1 pcs.

Electrical connection - plug

Connector: 1 x M12, angled; Moulded body: TPU; Locking: brass, nickel-plated



E70054




Connection cable

VDOAH040MSS0001A04STAH040MSS

Electrical connection


Cable: 1 m, PUR / PVC, orange, Ø 5 mm; 4 x 0.25 mm²

Connection

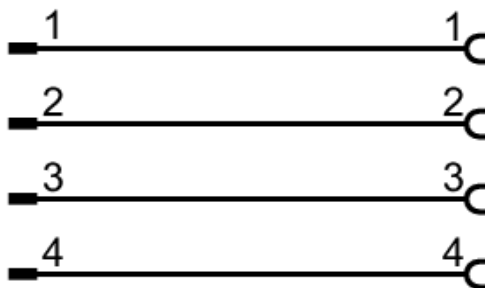

Electrical connection - socket

 Connector: 1 x M12, angled; Moulded body: TPU; Locking: brass, nickel-plated



Article no longer available - archive entry