




Induktiver Sensor

IFKC004BASKG/M/US-104-DRS/2LED

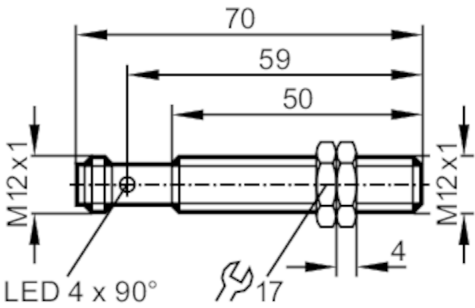

Product characteristics		
Electrical design		PNP/NPN
Output function		normally open
Sensing range	[mm]	4
Housing		threaded type
Dimensions	[mm]	M12 x 1 / L = 70
Application		
Special feature	Vergoldete Kontakte; Erhöhter Schaltabstand; Optische Einstellhilfe	
Application	Industrial applications / factory automation	
Electrical data		
Operating voltage	[V]	10...30 DC
Current consumption	[mA]	12; (24 V)
Protection class		II
Reverse polarity protection		ja
Outputs		
Electrical design		PNP/NPN
Output function		normally open
Max. voltage drop switching output DC	[V]	2,8
Minimum load current	[mA]	2; (nur im 2-Leiter Betrieb)
Max. leakage current	[mA]	0.6; (nur im 2-Leiter Betrieb)
Permanent current rating of switching output DC	[mA]	100
Switching frequency DC	[Hz]	700
Short-circuit protection		yes
Type of short-circuit protection		pulsed
Overload protection		yes
Detection zone		
Sensing range	[mm]	4
Real sensing range Sr	[mm]	4 ± 10 %
Operating distance	[mm]	0...3,24



Induktiver Sensor

IFKC004BASKG/M/US-104-DRS/2LED

Increased sensing range	yes
-------------------------	-----

Accuracy / deviations

Correction factor	steel: 1 / stainless steel: 0.7 / brass: 0.5 / aluminium: 0.4 / copper: 0.3	
Hysteresis [% of Sr]	1...20	
Switch point drift [% of Sr]	-10...10	

Operating conditions

Ambient temperature [°C]	-25...70
Protection	IP 67

Tests / approvals

EMC	EN 61000-4-2 ESD	4 kV CD / 8 kV AD
	EN 61000-4-3 HF radiated	10 V/m
	EN 61000-4-4 Burst	2 kV
	EN 61000-4-6 HF conducted	10 V
	EN 55011	class B

UL approval	
-------------	--

Mechanical data

Housing	threaded type
Mounting	flush mountable
Dimensions [mm]	M12 x 1 / L = 70
Thread designation	M12 x 1
Materials	brass white bronze coated; sensing face: PBT
Tightening torque [Nm]	7

Displays / operating elements

Display	switching status	4 x 90° LED, yellow
	setting aid	1 x LED, red
Optical setting aid	yes	

Accessories

Items supplied	lock nuts: 2
----------------	--------------

Remarks

Remarks	suitable for PLC type 1 according to IEC 61131-2
Pack quantity	1 Stück

Induktiver Sensor

IFKC004BASKG/M/US-104-DRS/2LED

Electrical connection - plug

Connector: 1 x M12; coding: A; Contacts: gold-plated

