


# E10105



## Connecting cable with socket

ADOGB030PLS0005E03


Article no longer available - archive entry

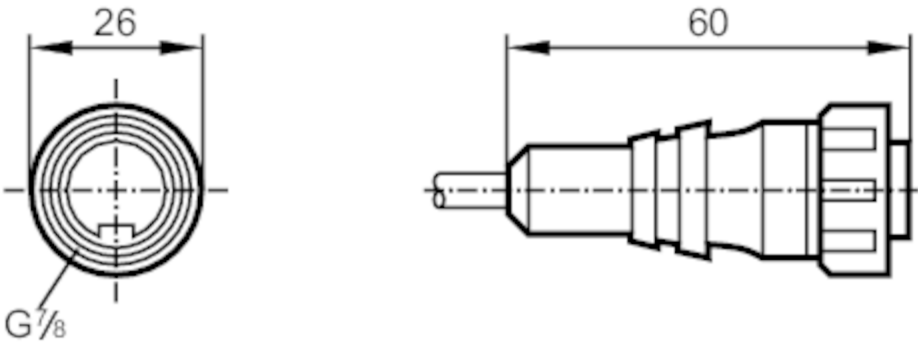

| Electrical data       |      |              |
|-----------------------|------|--------------|
| Operating voltage     | [V]  | 10...30 DC   |
| Operating conditions  |      |              |
| Ambient temperature   | [°C] | -40...90     |
| Protection            |      | IP 68        |
| Mechanical data       |      |              |
| Dimensions            | [mm] | 26 x 26 x 60 |
| Materials             |      | TPU          |
| Moulded-body material |      | TPU          |
| Material nut          |      | PA           |
| Remarks               |      |              |
| Pack quantity         |      | 1 pcs.       |

| Electrical connection                                          |  |
|----------------------------------------------------------------|--|
| Cable: 5 m, PVC, orange, Ø 5 mm; 3 x 0.75 mm² (22 x Ø 0.2 mm ) |  |

| Electrical connection - socket                                           |  |
|--------------------------------------------------------------------------|--|
| Connector: 1 x 7/8", straight; coding: A; Moulded body: TPU; Locking: PA |  |

 


# E10105



## Connecting cable with socket

ADOGB030PLS0005E03

### Connection

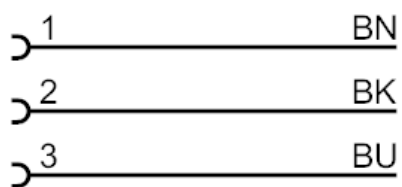

|      |                |       |
|------|----------------|-------|
| BK = | Core colours : | black |
| BN = |                | brown |
| BU = |                | blue  |