




## Fibre optic diffuse reflection sensor

FT-30-A-A-M8/3M

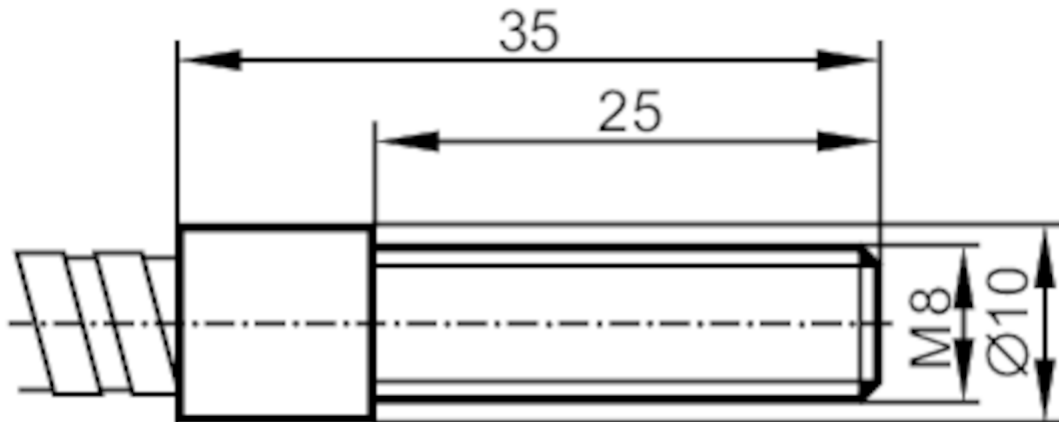

Application	
Function principle	Diffuse reflection sensor
Detection zone	
Range with fibre optic amplifier type	OIF
OIF	
Range fibre optics [mm]	45
Operating conditions	
Ambient temperature [°C]	-40...290
Mechanical data	
Weight [g]	241.3
Version of sensing head	straight
Sensing head thread	M8
Total length [mm]	3000
Min. bending radius [mm]	30; (for fixed installation)
Fibre arrangement	⓪
Materials	Adapter: PA
Fibre material	glass
Fibre head material	aluminium
Fibre sheath material	aluminium

# E20137



## Fibre optic diffuse reflection sensor

FT-30-A-A-M8/3M

Accessories	
Accessories (supplied)	hexagon nuts: 2 x M8, stainless steel
	tooth lock washers: 2
	knurled nut: 1 x M30
Remarks	
Pack quantity	1 pcs.