


Fibre optic diffuse reflection sensor

FT-00-A-A-M6/1,3M

Article no longer available - archive entry

Alternative articles: E20086

When selecting an alternative article and accessories please note that technical data may differ!

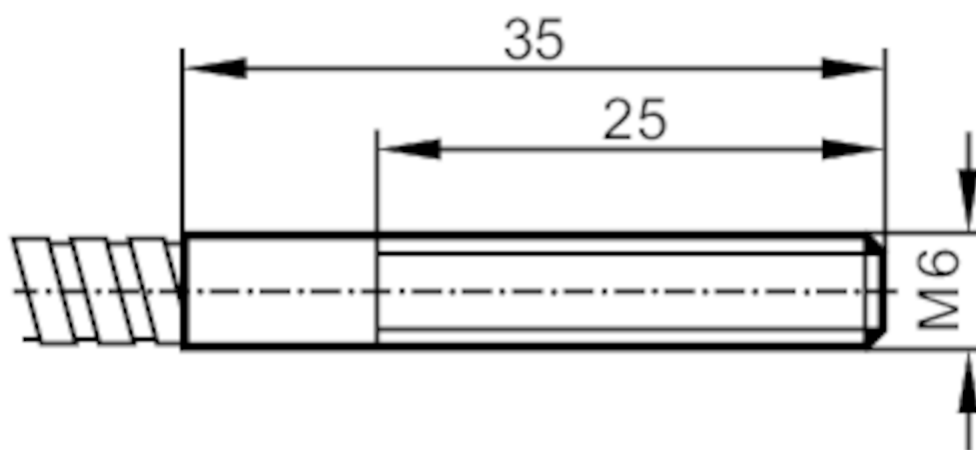

Application

Function principle	Diffuse reflection sensor
--------------------	---------------------------

Detection zone

Range with fibre optic amplifier type	OKF; OUF
---------------------------------------	----------

OKF

Range fibre optics [mm]	40
-------------------------	----

OUF

Range fibre optics [mm]	40
-------------------------	----

Operating conditions

Ambient temperature [°C]	-40...290
--------------------------	-----------

Mechanical data

Version of sensing head	straight
Sensing head thread	M6
Sensing head length [mm]	35
Total length [mm]	1300

E20242



Fibre optic diffuse reflection sensor

FT-00-A-A-M6/1,3M

Min. bending radius	[mm]	20
Materials		Adapter: ABS
Fibre material		glass
Fibre head material		aluminium
Fibre sheath material		aluminium
Remarks		
Pack quantity		1 pcs.