

E20246




Fibre optic diffuse reflection sensor

FT-30-A-A-M8/4M

Article no longer available - archive entry

Alternative article: E20152 When selecting an alternative article and accessories please note that technical data may differ! – When selecting an alternative article and accessories please note that technical data may differ!

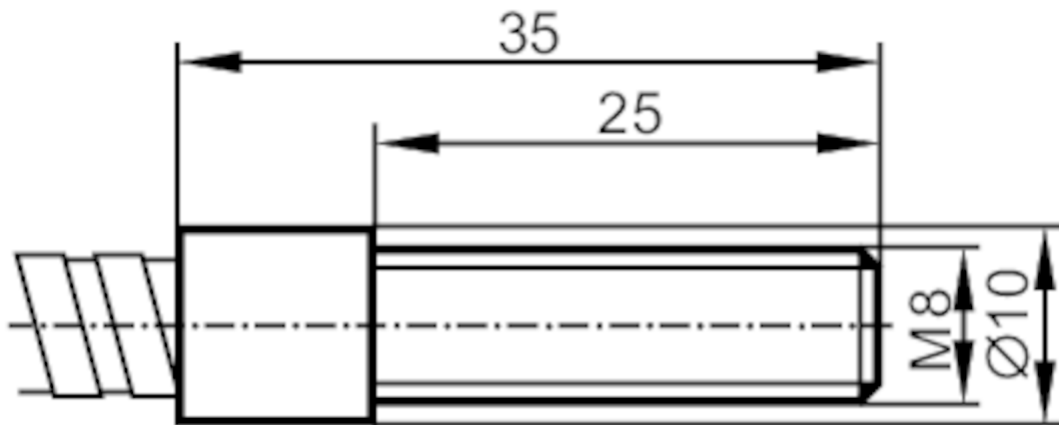

Application	
Function principle	Diffuse reflection sensor
Detection zone	
Range with fibre optic amplifier type	OIF
OIF	
Range fibre optics [mm]	36
Operating conditions	
Ambient temperature [°C]	-40...290
Mechanical data	
Version of sensing head	angled
Sensing head thread	M8
Total length [mm]	4000
Min. bending radius [mm]	30
Materials	Adapter: PA
Fibre material	glass
Fibre head material	aluminium
Fibre sheath material	aluminium

E20246



Fibre optic diffuse reflection sensor

FT-30-A-A-M8/4M

Remarks

Pack quantity

1 pcs.

Article no longer available - archive entry

Alternative article: E20152 When selecting an alternative article and accessories please note that technical data may differ! – When selecting an alternative article and accessories please note that technical data may differ!