





Cablu de conectare USB

USB/M12 CABLE

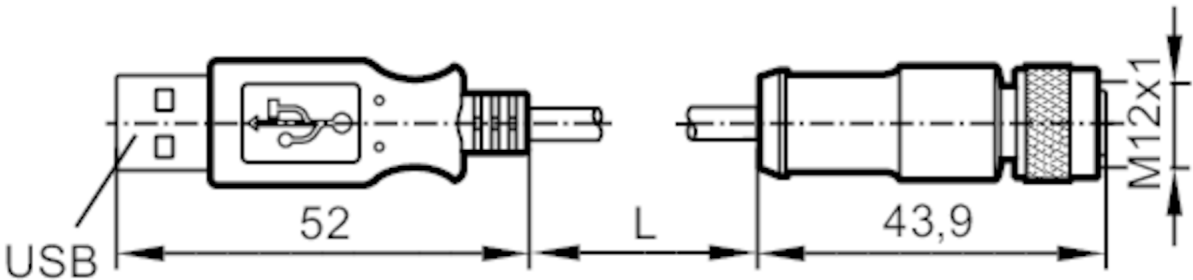

Aplicatie	
Caracteristici speciale	contacte aurite; cablu ecranat
Date electrice	
Tensiune de lucru [V]	5 DC
Clasa de protectie	III
Curent total Max. [A]	4
Interfete	
USB	
Versiune	2.0 A
Date mecanice	
Greutate [g]	50,8
Observatii	
Unitate de ambalare	1 buc.
Conectare electrică - mufa USB	

 Conector: 1 x USB, drept






Cablu de conectare USB

USB/M12 CABLE

Conectare electrică

Cablu: 1 m, PUR, Ø 4,5 mm, ecranat

Racord

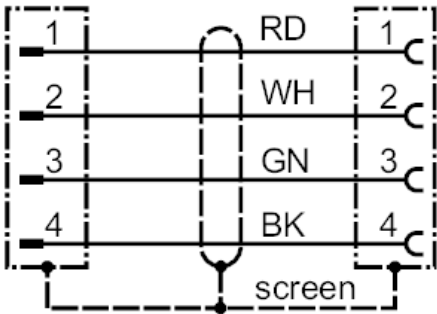

RD	roșu
WH	alb
GN	verde
BK	negru
screen	Ecran

1	VBUS
2	D-
3	D+
4	GND

Conectare electrică - Conector mama

Conector: 1 x M12, drept; codificare: B; Contacte: aurit

